

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0732045213

Status:

Active

Overview:

TNC RF Connectors

Description:


50 Ohms, TNC Right-Angle, PCB, Jack Receptacle, Body Nickel Plated Brass

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	RF/Coax Connectors
Series	73204
Overview	TNC RF Connectors
Product Name	TNC
Style	PCB
Type	Miniature
UPC	800753691575
Wire/Cable Type	N/A
Physical	
Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	None
Net Weight	15.797/g
Orientation	Right Angle
PCB Mounting	Through Hole
PCB Thickness - Recommended	2.40mm
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Electrical	
Frequency	11 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73204-5213, SD-73216-273

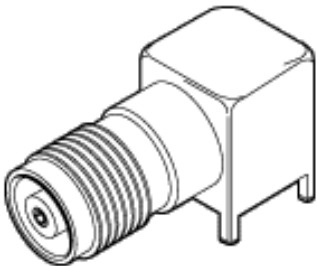

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Contained Per -ED/01/2018 (15 January 2018)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit <a href="#">Contact US</a>	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73204 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION