

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0733910320
Status: Active
Overview: SMA RF Connectors
Description: 50 Ohms, SMA Jack, Right-Angle, PCB with Reverse Polarity, 0.25µm Gold Plated Contact, 0.025µm Gold Plated Body and Cap

Documents:
[3D Model \(PDF\)](#)
[3D Model](#)
[Drawing \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family RF/Coax Connectors
Series 73391
Overview SMA RF Connectors
Product Name SMA
Style PCB
Type Subminiature
UPC 800756586489
Wire/Cable Type N/A


Physical
Gender Jack
Keying to Mating Part None
Net Weight 2.862/g
Orientation Right Angle
PCB Mounting Through Hole
Packaging Type Tray
Panel Mount No
Panel Mount Method N/A
Reverse Polar Yes

Electrical
Frequency 18 GHz
Impedance 50Ω
Power / Voltage VOLTAGE: 500 Vrms@Sea Level

Solder Process Data
Duration at Max. Process Temperature (seconds) 005
Lead-freeProcess Capability SMC&WAVE
Max. Cycles at Max. Process Temperature 001
Process Temperature max. C 260

Material Info

Reference - Drawing Numbers
Sales Drawing SD-73391-032-001

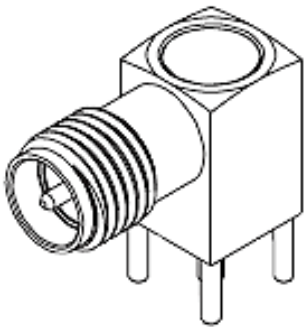

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)4578-DC (25 June 2020)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
73391 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION