

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0732511040

Status:


Active

Overview:

SMA RF Connectors

Description:

50 Ohms, SMA Jack, Reverse Polar, Edge Mount, for 1.57mm (.062") PCB

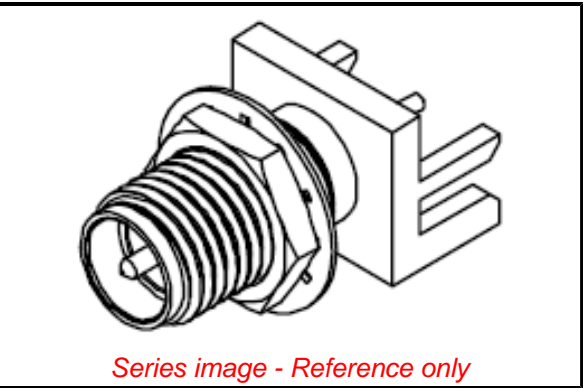

Documents:	
3D Model	Packaging Specification SD-73251-1040-PKG (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	

General	
Product Family	RF/Coax Connectors
Series	73251
Overview	SMA RF Connectors
Product Name	SMA
Style	PCB
Type	Subminiature
UPC	822348495542
Wire/Cable Type	N/A
Physical	
Gender	Jack
Keying to Mating Part	None
Net Weight	3.179/g
Orientation	Straight
PCB Mounting	Edge Mount
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Panel Mount	Yes
Panel Mount Method	Bulkhead
Reverse Polar	Yes
Electrical	
Frequency	18 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SD-73251-1040-PKG
Sales Drawing	SD-73251-104-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73251 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION