


Product- information Type: DI655/10

Group: Insulating and mounting accessories

Distance bolts from brass

Length:	10 mm
Thread:	M3
Key width:	5.5 SW
External thread length (GLA):	8 mm
Internal thread length (GLI):	6 mm
Material:	Brass
Finish:	nickel plated

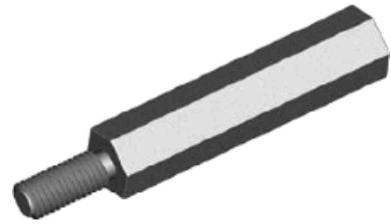

Distance Bolts from Brass

- + Material: Brass, Cu Zn 39 Pb 3, according to DIN 17660
- + Surface: nickel plated, G3 E, according to DIN 267
- + Minimum tensile strength: 430 N/mm²
- + Tolerance (distance dimension): +/-0.1 mm
- * = Thread through

The standard lengths listed are most likely in stock.
Special dimensions, lengths up to 100 mm and wrench sizes up to SW 13 upon request.

