

SPECIFICATION SHEET

**HDBaseT Over Cat5 Extender Receiver - Scaler/De-embedder**

- Supports distances up to 230ft
- Maximum Video Resolution Supported:
 - 1920 x 1080 (Full HD)
 - 1920 x 1200 (WUXGA)
- Optional Audio de-embedder if external sound system preferred
- RJ12 Port for system control
- TAA compliant

Specifications: HDBaseT Over Cat5 Extender Receiver - Scaler/De-embedder

Electrical Characteristics:


Max Resolutions Supported:	WUXGA (1920 x 1200) Full HD (1920 x 1080p)
Maximum Distance Supported:	230ft
System Control:	RJ12 Port

Power Adapter

Input Voltage:	100 ~240V, @ 50~60Hz
Input Current:	0.6A
Output Voltage:	18V
Output Current:	1.0A
Cable Length:	59" (1530 ± 100mm)
Pin DIA:	OD=4.7mm, ID=1.7mm
Center Pin Polarity:	Positive

Physical Characteristics:

Operating Temperature:	0°C ~ 40° C
Storage Temperature:	-10°C ~ 60°C
Humidity:	0~80% RH (non-condensing)
Weight:	1.99 lbs
Dimensions (HxWxD):	1.44 x 5.51 x 3.35in
Enclosure:	Metal
Approvals:	CE

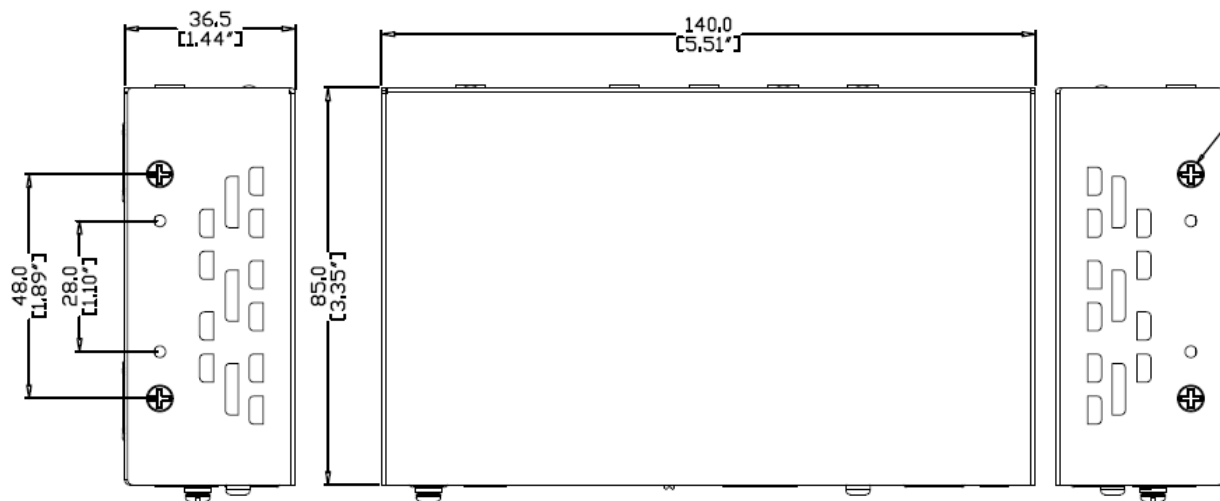

Part Number	Description
29372	HDBaseT Over Cat5 Extender Receiver - Scaler/De-embedder
29306	HDMI®, VGA + Stereo Audio to HDMI HDBaseT over Cat5 Extender Kit - Scaler/De-embedder
29307	HDMI® HDBaseT Over Cat5 Extender Kit - De-embedder



CABLES TO GO

Cables To Go
3555 Kettering Blvd.
Moraine, OH 45439
Phone: 800.287.2843
www.c2g.com

Follow Us

