

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0732160050

Status:


Active

Overview:

TNC RF Connectors

Description:

50 Ohms, TNC Plug, Right-Angle for RG-141, RG-303 and RG-58 Cable

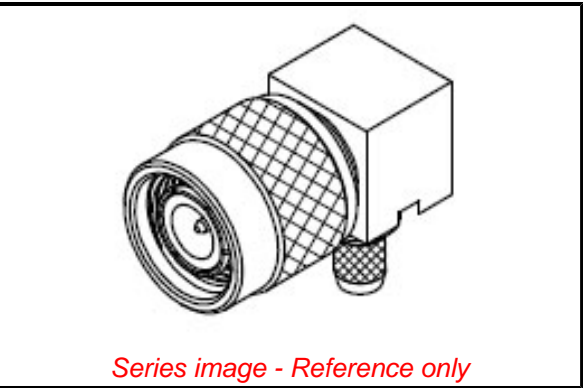

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	RF/Coax Connectors
Series	73216
Overview	TNC RF Connectors
Product Name	TNC
Style	Cable
Type	Miniature
UPC	800756008653
Wire/Cable Type	RG-141, RG-303, RG-58
Physical	
Gender	Plug
Keying to Mating Part	None
Net Weight	21.987/g
Orientation	Right Angle
PCB Mounting	Through Hole
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No
Electrical	
Frequency	11 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73216-005

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ECHA_01_2020 (16 January 2020)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit <a href="#">Contact US</a>	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73216 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION