


Model No.: **GN24A**

FOR INDUSTRIAL MARKET ONLY

NO MERCURY AND CADMIUM ADDED	
Description	: Mercury & Cadmium Free Alkaline Manganese Battery, AAA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: $\varnothing 10.5$ mm x 44.5 mm
Terminals	: Protruded positive (+) and flat negative (-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Warranty Period	: 36 months
Average Weight	: 11.4g


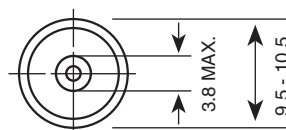


Cross References:

GP	JIS	IEC	Eveready	Duracell	Varta
24A	LR03	LR03	E92	MN2400	4003

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
20 Ohms	24 Hrs/ Day	0.9V	17.2H

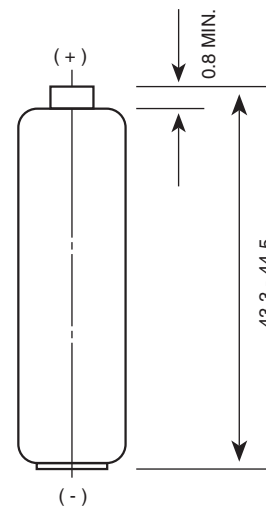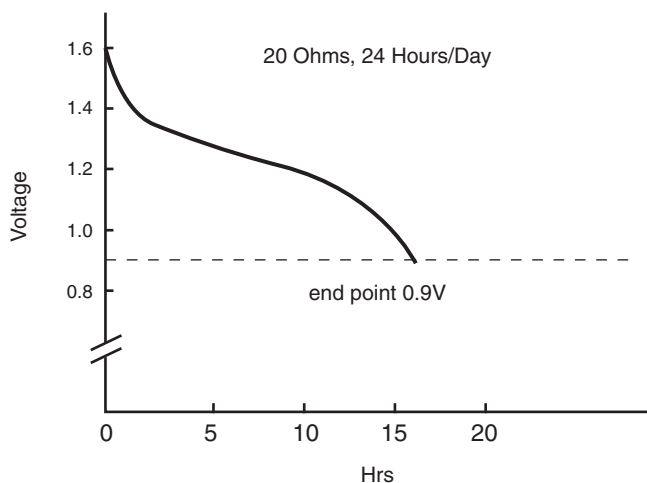

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

www.gpbatteries.com

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.
Copyright© GPI International Ltd. - All rights reserved

Member
Gold Peak Group

05110111092