

## 601 / 801 GP Series - Double Row Terminal Blocks



601 GP 06

### Specifications

- A Kulka® Brand
- 20 amps
- 300 Volts AC/DC, Class B/C
- 801 series (riveted construction) 150 volts AC/DC, Class C
- Base, phenolic, 150°C (UL RTI)
- JJ (GDI-30F) material available
- Screws, steel, #6-32 phil-slot
- Terminals, plated brass
- Open back design (Insulator strip required for voltage rating - [Reference](#))
- 1-23 poles at 7/16" centers
- Accepts lugs w/max width of .34"
- Bare wire range #12-#22 AWG

### Standards

- UL recognized file no. XCFR2.E47811
- CSA certified file no. LR19766
- CE Compliant (IEC 60947-7-1)
- RoHS compliant

 [Product Datasheet](#)

### Double Row Terminal Blocks - 601 / 801 GP Series

Catalog #	# of Poles	Dimensions	
		A	B
601 GP 01	1	1.19	0.88
601 GP 02	2	1.62	1.31
601 GP 03	3	2.06	1.75
601 GP 04	4	2.50	2.19
601 GP 05	5	2.94	2.63
601 GP 06	6	3.37	3.06
601 GP 07	7	3.81	3.50
601 GP 08	8	4.25	3.94
601 GP 09	9	4.69	4.38
601 GP 10	10	5.12	4.81
601 GP 11	11	5.56	5.25
601 GP 12	12	6.00	5.69
601 GP 13	13	6.44	6.13
601 GP 14	14	6.87	6.56
601 GP 15	15	7.31	7.00
601 GP 16	16	7.75	7.44
601 GP 17	17	8.19	7.88
601 GP 18	18	8.62	8.31
601 GP 19	19	9.06	8.75
601 GP 20	20	9.50	9.19
601 GP 21	21	9.94	9.63
601 GP 22	22	10.37	10.06
601 GP 23	23	10.81	10.50


mm = dim X 25.4

### Hardware Options

(Hardware options may affect ratings - Consult Customer Service)

Catalog #	Product Description	Reference Sheet
KT37	Full Quick Connect (0° Flat)	 <a href="#">Reference</a>
KT38	Full Quick Connect (45° Bend)	
KT39	Full Quick Connect (90° Bend)	
KT43	Half Quick Connect (0° Flat)	
KT44	Half Quick Connect (45° Flat)	
KT45	Half Quick Connect (90° Flat)	 <a href="#">Reference</a>
ST	Full Solder	
3/4 ST	Half Solder	
Y	Feed Thru Solder (.422)	
YSY	Feed Thru Solder (.687)	 <a href="#">Reference</a>
J 601	Line-to-Line Jumper	
601RJ(S)	Multiple Position Jumper	
3765	Wire Clamp Screw	 <a href="#">Reference</a>
3760	Wire Clamp Screw	
2102	Stud	 <a href="#">Reference</a>
2104	Feed Thru Solder	
2108	Individual Screw Terminals	
PSB	Phil-Slot Brass Screw	Consult Customer Service
	Covers - Top-Mounted	 <a href="#">Reference</a>
	Marking Strips & Insulator Strips - Sub-Mounted	 <a href="#">Reference</a>

Quick Connects: .020" x .187"

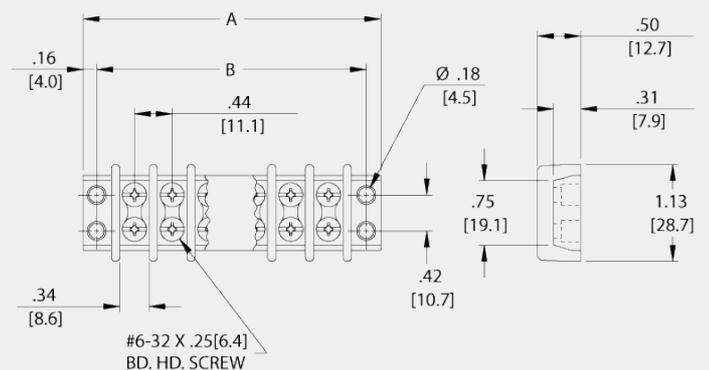

Marathon Special Products  
427 Van Camp Road  
P.O. Box 468  
Bowling Green, Ohio 43402

tel: 419-352-8441  
fax: 419-352-0875  
email: [marketing@marathonsp.com](mailto:marketing@marathonsp.com)

**CUSTOMER SERVICE HOURS**

Mon-Fri 8am-5pm EST

**About Us**

**Contact Us**

**Terms & Conditions**

**Locate a Distributor**

Marathon Special Products is an industry leader for supplying power blocks, terminal blocks, and fuse holders in North America. We've achieved this by providing one of the broadest line offerings with various sizes, terminal styles, electrical ratings and features.

