


Product- information Type: DI650/15

Group: Insulating and mounting accessories

Distance bolts from brass

Length:	15 mm
Thread:	M3
Key width:	5 SW
Internal thread length (GLI):	15 mm
Material:	Brass
Finish:	nickel plated

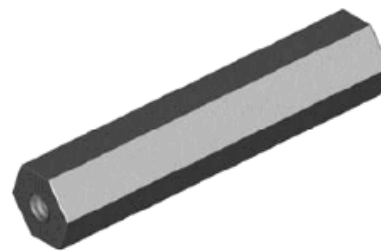

Distance Bolts from Brass

- + Material: Brass, Cu Zn 39 Pb 3, according to DIN 17660
- + Surface: nickel plated, G3 E, according to DIN 267
- + Minimum tensile strength: 430 N/mm²
- + Tolerance (distance dimension): +/-0.1 mm
- * = Thread through

The standard lengths listed are most likely in stock.

Special dimensions, lengths up to 100 mm and wrench sizes up to SW 13 upon request.

