

Bocube



Detailed product information can be found on www.bopla.de



- Patented, innovative, hinged quick-release catch technology without screws: open with a screwdriver, close by hand
- 22 sizes, 132 standard combinations possible
- 2 material types: ABS or PC UL 94 V0, flame-resistant and self-extinguishing
- PC material is suitable for outdoor use due to its f1-listing according to UL 746C
- Captive lid with membrane keypad area, available in 2 variants: grey or crystal-clear
- Elegant design, hinged quick-release catches available in different colours
- Excellent recyclability because of mono-material plastics without injection-moulded metal parts

Colour:

Graphite grey, similar to RAL 7024; light grey, similar to RAL 7035; special colours on request

Protection class:

IP 66/IP 67 DIN EN 60529

Enclosure material:

ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C), foamed seal; for details please see Technical Information

Unique, innovative, versatile enclosure made of ABS or polycarbonate UL 94 V0



Bocube consists of few parts, so it can easily be mounted by hand. Open it by means of a screwdriver (size 3).



All enclosures have a recessed area in the lid for mounting membrane keypads.



The hinged catch ensures that the lid is captive and can be used ideally as a display enclosure.



As an alternative to the hinged catch, the enclosures can be screwed. The hinged catch conceals the screws.



Wall brackets can be used for all Bocube sizes and are screwed into the drilling holes on the back of the enclosure base.



The blanking plugs allow the hinged side to be selected as required.



Rectangular front panels or PCBs can be mounted in the base (by using distance bolts) and in the lid.



Coloured hinges (tool-operated or hand-operated, as required). Transparent hinges available on request.



PC material is suitable for outdoor use due to its f1-listing according to UL 746C.


Bocube | Polycarbonate



Enclosures, polycarbonate UL 94 V0, single-coloured

Model	Order no.	A	B	C	a1	a2	b1	b2	c1	Colour
B 080805 PC-V0 7024	96011114	89	80	47	50	52,6	68	73,6	40,5	Graphite grey
B 080805 PC-V0 7035	96011115	89	80	47	50	52,6	68	73,6	40,5	Light grey
B 100806 PC-V0 7024	96012124	113	80	60	74	76,4	68	73,4	52	Graphite grey
B 100806 PC-V0 7035	96012125	113	80	60	74	76,4	68	73,4	52	Light grey
B 100809 PC-V0 7024	96012134	113	80	90	74	75,9	68	72,9	82	Graphite grey
B 100809 PC-V0 7035	96012135	113	80	90	74	75,9	68	72,9	82	Light grey
B 140804 PC-V0 7024	96013144	151	80	40	112	114,8	68	73,8	32	Graphite grey
B 140804 PC-V0 7035	96013145	151	80	40	112	114,8	68	73,8	32	Light grey
B 140806 PC-V0 7024	96013124	151	80	60	112	114,4	68	73,4	52	Graphite grey
B 140806 PC-V0 7035	96013125	151	80	60	112	114,4	68	73,4	52	Light grey
B 140809 PC-V0 7024	96013134	151	80	90	112	113,9	68	72,9	82	Graphite grey
B 140809 PC-V0 7035	96013135	151	80	90	112	113,9	68	72,9	82	Light grey
B 141306 PC-V0 7024	96013224	151	125	60	112	114,4	113	118,4	52	Graphite grey
B 141306 PC-V0 7035	96013225	151	125	60	112	114,4	113	118,4	52	Light grey
B 141309 PC-V0 7024	96013234	151	125	90	112	113,9	113	117,9	82	Graphite grey
B 141309 PC-V0 7035	96013235	151	125	90	112	113,9	113	117,9	82	Light grey
B 180806 PC-V0 7024	96014124	191	80	60	152	154,4	68	73,4	52	Graphite grey
B 180806 PC-V0 7035	96014125	191	80	60	152	154,4	68	73,4	52	Light grey
B 180809 PC-V0 7024	96014134	191	80	90	152	153,9	68	72,9	82	Graphite grey
B 180809 PC-V0 7035	96014135	191	80	90	152	153,9	68	72,9	82	Light grey
B 181304 PC-V0 7024	96014244	191	125	40	152	154,6	113	118,8	32	Graphite grey
B 181304 PC-V0 7035	96014245	191	125	40	152	154,6	113	118,8	32	Light grey
B 181306 PC-V0 7024	96014224	191	125	60	152	154,4	113	118,4	52	Graphite grey
B 181306 PC-V0 7035	96014225	191	125	60	152	154,4	113	118,4	52	Light grey
B 181309 PC-V0 7024	96014234	191	125	90	152	153,9	113	117,9	82	Graphite grey
B 181309 PC-V0 7035	96014235	191	125	90	152	153,9	113	117,9	82	Light grey
B 221304 PC-V0 7024	96015244	231	125	40	192	194,6	113	118,8	32	Graphite grey
B 221304 PC-V0 7035	96015245	231	125	40	192	194,6	113	118,8	32	Light grey
B 221306 PC-V0 7024	96015224	231	125	60	192	194,4	113	118,4	52	Graphite grey
B 221306 PC-V0 7035	96015225	231	125	60	192	194,4	113	118,4	52	Light grey
B 221309 PC-V0 7024	96015234	231	125	90	192	194,1	113	117,9	82	Graphite grey
B 221309 PC-V0 7035	96015235	231	125	90	192	194,1	113	117,9	82	Light grey
B 261704 PC-V0 7024	96016344	271	170	40	232	234,8	158	163,8	31,5	Graphite grey
B 261704 PC-V0 7035	96016345	271	170	40	232	234,8	158	163,8	31,5	Light grey
B 261706 PC-V0 7024	96016324	271	170	60	232	234,4	158	163,4	51,5	Graphite grey
B 261706 PC-V0 7035	96016325	271	170	60	232	234,4	158	163,4	51,5	Light grey
B 261709 PC-V0 7024	96016334	271	170	90	232	234,1	158	163,1	81,5	Graphite grey
B 261709 PC-V0 7035	96016335	271	170	90	232	234,1	158	163,1	81,5	Light grey
B 261712 PC-V0 7024	96016364	271	170	120	232	233,4	158	162,4	111,5	Graphite grey
B 261712 PC-V0 7035	96016365	271	170	120	232	233,4	158	162,4	111,5	Light grey
B 233012 PC-V0 7024	96018564	239	300	120	186	188,1	288	289,5	109	Graphite grey
B 233012 PC-V0 7035	96018565	239	300	120	186	188,1	288	289,5	109	Light grey
B 273612 PC-V0 7024	96017664	284	364	120	231	233,1	352	353,5	109	Graphite grey
B 273612 PC-V0 7035	96017665	284	364	120	231	233,1	352	353,5	109	Light grey

Scope of delivery: Lid and base, hinged quick-release catches

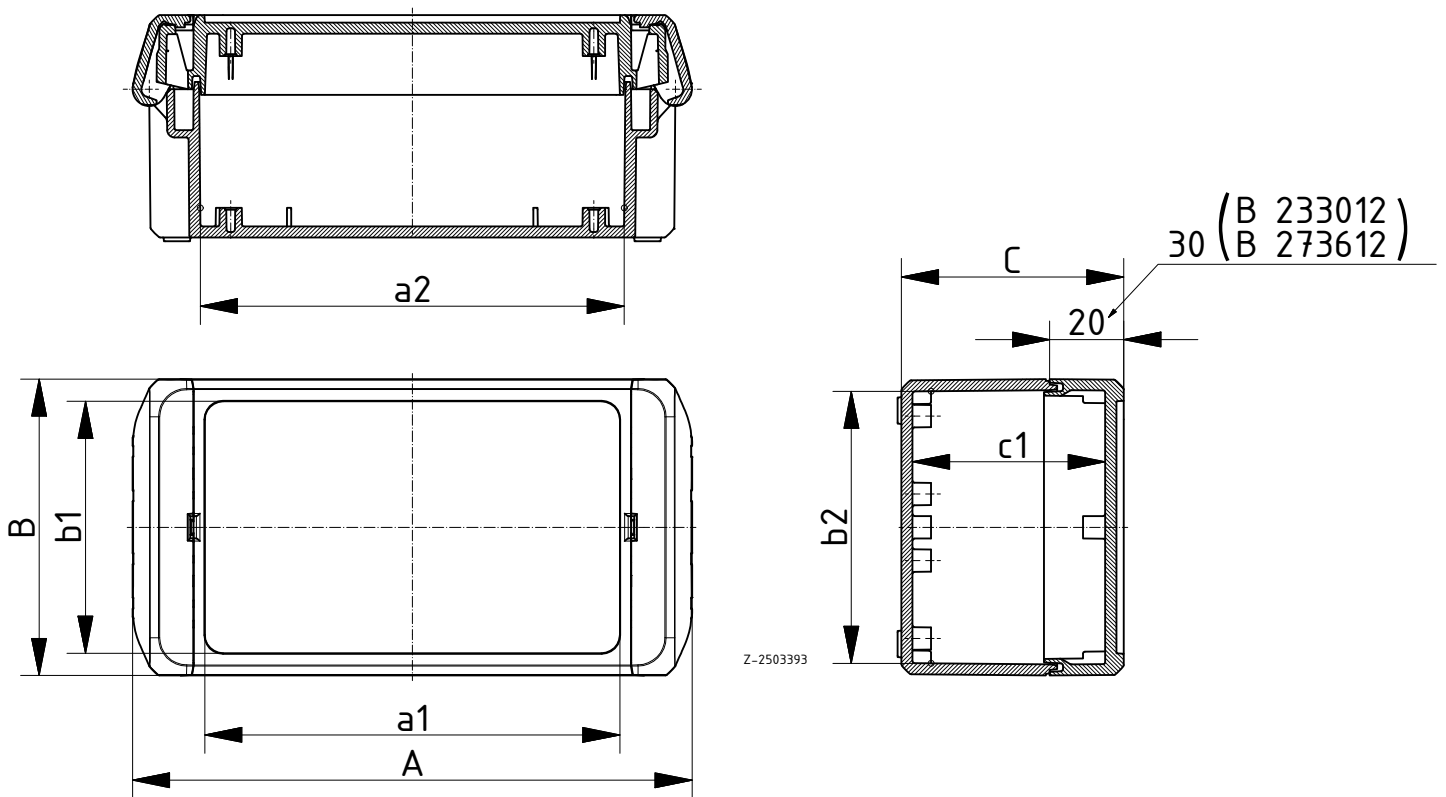


Bocube | Polycarbonate



Enclosures, polycarbonate UL 94 V0, crystal-clear lid

Model	Order no.	A	B	C	a1	a2	b1	b2	c1	Colour
B 080805 PC-V0-G 7024	96021114	89	80	47	50	52,6	68	73,6	40,5	Graphite grey
B 080805 PC-V0-G 7035	96021115	89	80	47	50	52,6	68	73,6	40,5	Light grey
B 100806 PC-V0-G 7024	96022124	113	80	60	74	76,4	68	73,4	52	Graphite grey
B 100806 PC-V0-G 7035	96022125	113	80	60	74	76,4	68	73,4	52	Light grey
B 100809 PC-V0-G 7024	96022134	113	80	90	74	75,9	68	72,9	82	Graphite grey
B 100809 PC-V0-G 7035	96022135	113	80	90	74	75,9	68	72,9	82	Light grey
B 140804 PC-V0-G 7024	96023144	151	80	40	112	114,8	68	73,8	32	Graphite grey
B 140804 PC-V0-G 7035	96023145	151	80	40	112	114,8	68	73,8	32	Light grey
B 140806 PC-V0-G 7024	96023124	151	80	60	112	114,4	68	73,4	52	Graphite grey
B 140806 PC-V0-G 7035	96023125	151	80	60	112	114,4	68	73,4	52	Light grey
B 140809 PC-V0-G 7024	96023134	151	80	90	112	113,9	68	72,9	82	Graphite grey
B 140809 PC-V0-G 7035	96023135	151	80	90	112	113,9	68	72,9	82	Light grey
B 141306 PC-V0-G 7024	96023224	151	125	60	112	114,4	113	118,4	52	Graphite grey
B 141306 PC-V0-G 7035	96023225	151	125	60	112	114,4	113	118,4	52	Light grey
B 141309 PC-V0-G 7024	96023234	151	125	90	112	113,9	113	117,9	82	Graphite grey
B 141309 PC-V0-G 7035	96023235	151	125	90	112	113,9	113	117,9	82	Light grey
B 180806 PC-V0-G 7024	96024124	191	80	60	152	154,4	68	73,4	52	Graphite grey
B 180806 PC-V0-G 7035	96024125	191	80	60	152	154,4	68	73,4	52	Light grey
B 180809 PC-V0-G 7024	96024134	191	80	90	152	153,9	68	72,9	82	Graphite grey
B 180809 PC-V0-G 7035	96024135	191	80	90	152	153,9	68	72,9	82	Light grey
B 181304 PC-V0-G 7024	96024244	191	125	40	152	154,6	113	118,8	32	Graphite grey
B 181304 PC-V0-G 7035	96024245	191	125	40	152	154,6	113	118,8	32	Light grey
B 181306 PC-V0-G 7024	96024224	191	125	60	152	154,4	113	118,4	52	Graphite grey
B 181306 PC-V0-G 7035	96024225	191	125	60	152	154,4	113	118,4	52	Light grey
B 181309 PC-V0-G 7024	96024234	191	125	90	152	153,9	113	117,9	82	Graphite grey
B 181309 PC-V0-G 7035	96024235	191	125	90	152	153,9	113	117,9	82	Light grey
B 221304 PC-V0-G 7024	96025244	231	125	40	192	194,6	113	118,8	32	Graphite grey
B 221304 PC-V0-G 7035	96025245	231	125	40	192	194,6	113	118,8	32	Light grey
B 221306 PC-V0-G 7024	96025224	231	125	60	192	194,4	113	118,4	52	Graphite grey
B 221306 PC-V0-G 7035	96025225	231	125	60	192	194,4	113	118,4	52	Light grey
B 221309 PC-V0-G 7024	96025234	231	125	90	192	194,1	113	117,9	82	Graphite grey
B 221309 PC-V0-G 7035	96025235	231	125	90	192	194,1	113	117,9	82	Light grey
B 261704 PC-V0-G 7024	96026344	271	170	40	232	234,8	158	163,8	31,5	Graphite grey
B 261704 PC-V0-G 7035	96026345	271	170	40	232	234,8	158	163,8	31,5	Light grey
B 261706 PC-V0-G 7024	96026324	271	170	60	232	234,4	158	163,4	51,5	Graphite grey
B 261706 PC-V0-G 7035	96026325	271	170	60	232	234,4	158	163,4	51,5	Light grey
B 261709 PC-V0-G 7024	96026334	271	170	90	232	234,1	158	163,1	81,5	Graphite grey
B 261709 PC-V0-G 7035	96026335	271	170	90	232	234,1	158	163,1	81,5	Light grey
B 261712 PC-V0-G 7024	96026364	271	170	120	232	233,4	158	162,4	111,5	Graphite grey
B 261712 PC-V0-G 7035	96026365	271	170	120	232	233,4	158	162,4	111,5	Light grey
B 233012 PC-V0-G 7024	96028564	239	300	120	186	188,1	288	289,5	109	Graphite grey
B 233012 PC-V0-G 7035	96028565	239	300	120	186	188,1	288	289,5	109	Light grey
B 273612 PC-V0-G 7024	96027664	284	364	120	231	233,1	352	353,5	109	Graphite grey
B 273612 PC-V0-G 7035	96027665	284	364	120	231	233,1	352	353,5	109	Light grey

Scope of delivery: Lid and base, hinged quick-release catches

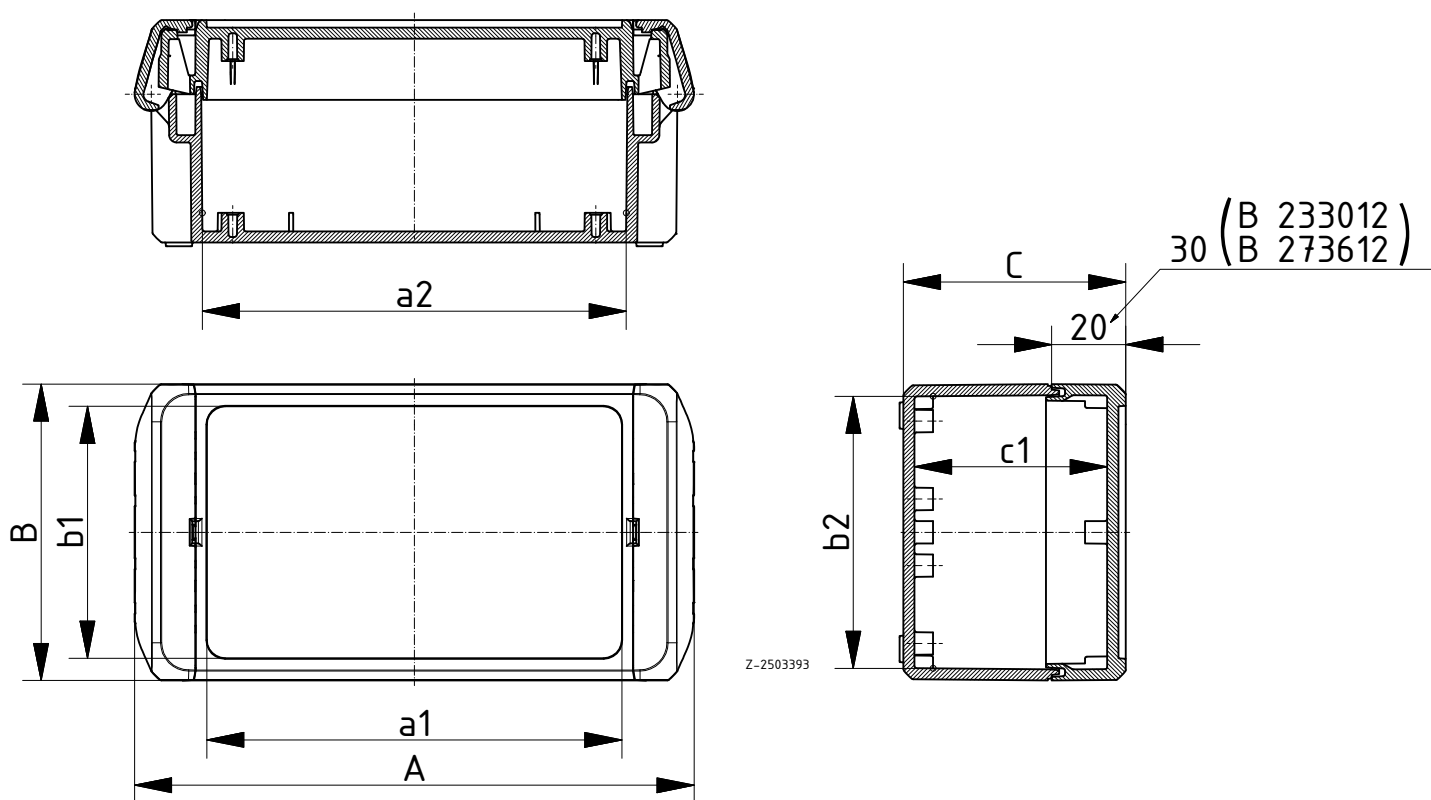

Bocube | ABS




Enclosures, ABS, single-coloured

Model	Order no.	A	B	C	a1	a2	b1	b2	c1	Colour
B 080805 ABS 7024	96031114	89	80	47	50	52,6	68	73,6	40,5	Graphite grey
B 080805 ABS 7035	96031115	89	80	47	50	52,6	68	73,6	40,5	Light grey
B 100806 ABS 7024	96032124	113	80	60	74	76,4	68	73,4	52	Graphite grey
B 100806 ABS 7035	96032125	113	80	60	74	76,4	68	73,4	52	Light grey
B 100809 ABS 7024	96032134	113	80	90	74	75,9	68	72,9	82	Graphite grey
B 100809 ABS 7035	96032135	113	80	90	74	75,9	68	72,9	82	Light grey
B 140804 ABS 7024	96033144	151	80	40	112	114,8	68	73,8	32	Graphite grey
B 140804 ABS 7035	96033145	151	80	40	112	114,8	68	73,8	32	Light grey
B 140806 ABS 7024	96033124	151	80	60	112	114,4	68	73,4	52	Graphite grey
B 140806 ABS 7035	96033125	151	80	60	112	114,4	68	73,4	52	Light grey
B 140809 ABS 7024	96033134	151	80	90	112	113,9	68	72,9	82	Graphite grey
B 140809 ABS 7035	96033135	151	80	90	112	113,9	68	72,9	82	Light grey
B 141306 ABS 7024	96033224	151	125	60	112	114,4	113	118,4	52	Graphite grey
B 141306 ABS 7035	96033225	151	125	60	112	114,4	113	118,4	52	Light grey
B 141309 ABS 7024	96033234	151	125	90	112	113,9	113	117,9	82	Graphite grey
B 141309 ABS 7035	96033235	151	125	90	112	113,9	113	117,9	82	Light grey
B 180806 ABS 7024	96034124	191	80	60	152	154,4	68	73,4	52	Graphite grey
B 180806 ABS 7035	96034125	191	80	60	152	154,4	68	73,4	52	Light grey
B 180809 ABS 7024	96034134	191	80	90	152	153,9	68	72,9	82	Graphite grey
B 180809 ABS 7035	96034135	191	80	90	152	153,9	68	72,9	82	Light grey
B 181304 ABS 7024	96034244	191	125	40	152	154,6	113	118,8	32	Graphite grey
B 181304 ABS 7035	96034245	191	125	40	152	154,6	113	118,8	32	Light grey
B 181306 ABS 7024	96034224	191	125	60	152	154,4	113	118,4	52	Graphite grey
B 181306 ABS 7035	96034225	191	125	60	152	154,4	113	118,4	52	Light grey
B 181309 ABS 7024	96034234	191	125	90	152	153,9	113	117,9	82	Graphite grey
B 181309 ABS 7035	96034235	191	125	90	152	153,9	113	117,9	82	Light grey
B 221304 ABS 7024	96035244	231	125	40	192	194,6	113	118,8	32	Graphite grey
B 221304 ABS 7035	96035245	231	125	40	192	194,6	113	118,8	32	Light grey
B 221306 ABS 7024	96035224	231	125	60	192	194,4	113	118,4	52	Graphite grey
B 221306 ABS 7035	96035225	231	125	60	192	194,4	113	118,4	52	Light grey
B 221309 ABS 7024	96035234	231	125	90	192	194,1	113	117,9	82	Graphite grey
B 221309 ABS 7035	96035235	231	125	90	192	194,1	113	117,9	82	Light grey
B 261704 ABS 7024	96036344	271	170	40	232	234,8	158	163,8	31,5	Graphite grey
B 261704 ABS 7035	96036345	271	170	40	232	234,8	158	163,8	31,5	Light grey
B 261706 ABS 7024	96036324	271	170	60	232	234,4	158	163,4	51,5	Graphite grey
B 261706 ABS 7035	96036325	271	170	60	232	234,4	158	163,4	51,5	Light grey
B 261709 ABS 7024	96036334	271	170	90	232	234,1	158	163,1	81,5	Graphite grey
B 261709 ABS 7035	96036335	271	170	90	232	234,1	158	163,1	81,5	Light grey
B 261712 ABS 7024	96036364	271	170	120	232	233,4	158	162,4	111,5	Graphite grey
B 261712 ABS 7035	96036365	271	170	120	232	233,4	158	162,4	111,5	Light grey
B 233012 ABS 7024	96038564	239	300	120	186	188,1	288	289,5	109	Graphite grey
B 233012 ABS 7035	96038565	239	300	120	186	188,1	288	289,5	109	Light grey
B 273612 ABS 7024	96037664	284	364	120	231	233,1	352	353,5	109	Graphite grey
B 273612 ABS 7035	96037665	284	364	120	231	233,1	352	353,5	109	Light grey

Scope of delivery: Lid and base, hinged quick-release catches

Note: Material shrinkage may result in ABS enclosures being approx. 0.1 – 0.25 % larger.

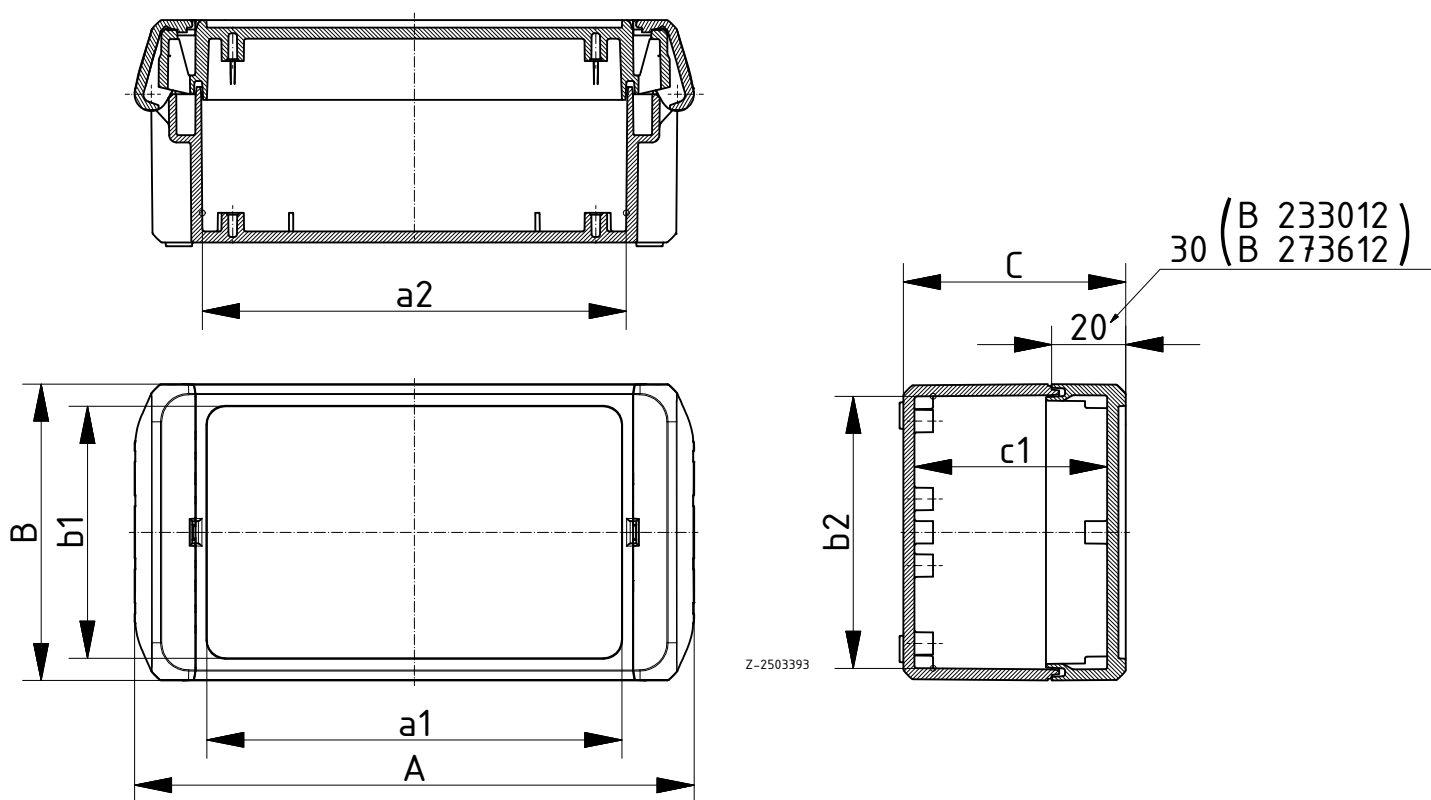

Bocube | Accessories

Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS



Model	Order no.	Colour	Note
B SC 08 PC-V0 1023	96310103	Traffic yellow	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 1023	96330103	Traffic yellow	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 PC-V0 7035	96310105	Light grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 7035	96330105	Light grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 PC-V0 7024	96310104	Graphite grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 7024	96330104	Graphite grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 PC-V0 6029	96310109	Mint green	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 6029	96330109	Mint green	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 PC-V0 5002	96310102	Ultramarine blue	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 5002	96330102	Ultramarine blue	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 PC-V0 3000	96310100	Flame red	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 08 ABS 3000	96330100	Flame red	For B 0808.., B 1008.., B 1408.., B 1808..
B SC 13 PC-V0 1023	96310203	Traffic yellow	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 1023	96330203	Traffic yellow	For B 1413.., B 1813.., B 2213..
B SC 13 PC-V0 7035	96310205	Light grey	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 7035	96330205	Light grey	For B 1413.., B 1813.., B 2213..
B SC 13 PC-V0 7024	96310204	Graphite grey	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 7024	96330204	Graphite grey	For B 1413.., B 1813.., B 2213..
B SC 13 PC-V0 6029	96310209	Mint green	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 6029	96330209	Mint green	For B 1413.., B 1813.., B 2213..
B SC 13 PC-V0 5002	96310202	Ultramarine blue	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 5002	96330202	Ultramarine blue	For B 1413.., B 1813.., B 2213..
B SC 13 PC-V0 3000	96310200	Flame red	For B 1413.., B 1813.., B 2213..
B SC 13 ABS 3000	96330200	Flame red	For B 1413.., B 1813.., B 2213..
B SC 17 PC-V0 1023	96310303	Traffic yellow	For B 2617..
B SC 17 ABS 1023	96330303	Traffic yellow	For B 2617..
B SC 17 PC-V0 7035	96310305	Light grey	For B 2617..
B SC 17 ABS 7035	96330305	Light grey	For B 2617..
B SC 17 PC-V0 7024	96310304	Graphite grey	For B 2617..
B SC 17 ABS 7024	96330304	Graphite grey	For B 2617..
B SC 17 PC-V0 6029	96310309	Mint green	For B 2617..
B SC 17 ABS 6029	96330309	Mint green	For B 2617..
B SC 17 PC-V0 5002	96310302	Ultramarine blue	For B 2617..
B SC 17 ABS 5002	96330302	Ultramarine blue	For B 2617..
B SC 17 PC-V0 3000	96310300	Flame red	For B 2617..
B SC 17 ABS 3000	96330300	Flame red	For B 2617..
B SC PC-V0 1023	96310003	Traffic yellow	For B 233012, B 273612
B SC ABS 1023	96330003	Traffic yellow	For B 233012, B 273612
B SC PC-V0 3000	96310000	Flame red	For B 233012, B 273612
B SC ABS 3000	96330000	Flame red	For B 233012, B 273612
B SC PC-V0 5002	96310002	Ultramarine blue	For B 233012, B 273612
B SC ABS 5002	96330002	Ultramarine blue	For B 233012, B 273612
B SC PC-V0 6029	96310009	Mint green	For B 233012, B 273612
B SC ABS 6029	96330009	Mint green	For B 233012, B 273612
B SC PC-V0 7024	96310004	Graphite grey	For B 233012, B 273612
B SC ABS 7024	96330004	Graphite grey	For B 233012, B 273612
B SC PC-V0 7035	96310005	Light grey	For B 233012, B 273612
B SC ABS 7035	96330005	Light grey	For B 233012, B 273612

Scope of delivery: B SC 08 - B SC 17 = 2 pcs. tool-operated; B SC = 4 pcs. tool-operated

Bocube | Accessories

Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

Model	Order no.	Colour	Note
B SC HB 08 PC-V0 1023	96910103	Traffic yellow	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 1023	96930103	Traffic yellow	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 PC-V0 7035	96910105**	Light grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 7035	96930105**	Light grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 PC-V0 7024	96910104**	Graphite grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 7024	96930104**	Graphite grey	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 PC-V0 6029	96910109	Mint green	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 6029	96930109	Mint green	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 PC-V0 5002	96910102	Ultramarine blue	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 5002	96930102	Ultramarine blue	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 ABS 3000	96930100	Flame red	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 08 PC-V0 3000	96910100	Flame red	For B 0808.., B 1008.., B 1408.., B 1808..
B SC HB 13 PC-V0 1023	96910203	Traffic yellow	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 1023	96930203	Traffic yellow	For B 1413.., B 1813.., B 2213..
B SC HB 13 PC-V0 7035	96910205**	Light grey	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 7035	96930205**	Light grey	For B 1413.., B 1813.., B 2213..
B SC HB 13 PC-V0 7024	96910204**	Graphite grey	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 7024	96930204**	Graphite grey	For B 1413.., B 1813.., B 2213..
B SC HB 13 PC-V0 6029	96910209	Mint green	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 6029	96930209	Mint green	For B 1413.., B 1813.., B 2213..
B SC HB 13 PC-V0 5002	96910202	Ultramarine blue	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 5002	96930202	Ultramarine blue	For B 1413.., B 1813.., B 2213..
B SC HB 13 PC-V0 3000	96910200	Flame red	For B 1413.., B 1813.., B 2213..
B SC HB 13 ABS 3000	96930200	Flame red	For B 1413.., B 1813.., B 2213..
B SC HB 17 PC-V0 1023	96910303	Traffic yellow	For B 2617..
B SC HB 17 ABS 1023	96930303	Traffic yellow	For B 2617..
B SC HB 17 PC-V0 7035	96910305**	Light grey	For B 2617..
B SC HB 17 ABS 7035	96930305**	Light grey	For B 2617..
B SC HB 17 PC-V0 7024	96910304**	Graphite grey	For B 2617..
B SC HB 17 ABS 7024	96930304**	Graphite grey	For B 2617..
B SC HB 17 PC-V0 6029	96910309	Mint green	For B 2617..
B SC HB 17 ABS 6029	96930309	Mint green	For B 2617..
B SC HB 17 PC-V0 5002	96910302	Ultramarine blue	For B 2617..
B SC HB 17 ABS 5002	96930302	Ultramarine blue	For B 2617..
B SC HB 17 PC-V0 3000	96910300	Flame red	For B 2617..
B SC HB 17 ABS 3000	96930300	Flame red	For B 2617..
B SC HB PC-V0 1023	96910003	Traffic yellow	For B 233012, B 273612
B SC HB ABS 1023	96930003	Traffic yellow	For B 233012, B 273612
B SC HB PC-V0 7035	96910005**	Light grey	For B 233012, B 273612
B SC HB ABS 7035	96930005**	Light grey	For B 233012, B 273612
B SC HB PC-V0 7024	96910004**	Graphite grey	For B 233012, B 273612
B SC HB ABS 7024	96930004**	Graphite grey	For B 233012, B 273612
B SC HB PC-V0 6029	96910009	Mint green	For B 233012, B 273612
B SC HB ABS 6029	96930009	Mint green	For B 233012, B 273612
B SC HB PC-V0 5002	96910002	Ultramarine blue	For B 233012, B 273612
B SC HB ABS 5002	96930002	Ultramarine blue	For B 233012, B 273612
B SC HB PC-V0 3000	96910000	Flame red	For B 233012, B 273612
B SC HB ABS 3000	96930000	Flame red	For B 233012, B 273612



Scope of delivery: B SC 08 - B SC 17 = 1 pc. tool-operated and 1 pc. manually-operated; B SC = 2 pcs. tool-operated and 2 pcs. manually-operated

Note: IP protection class only guaranteed with closed hinged catch.

** To order ONLY the hand-operated hinge, please order the a.m. article number plus ".E" (e.g. 96930105.E)

Bocube | Accessories



Wall brackets

Model	Order no.	Colour	Note
B WL 7024	96510004	Graphite grey	For B 08... - B 26...
B WL 7035	96510005	Light grey	For B 08... - B 26...
B WL-2 7024	96510604	Graphite grey	For B 2330.., B 2736..
B WL-2 7035	96510605	Light grey	For B 2330.., B 2736..

Scope of delivery: 4 wall brackets (polycarbonate UL 94 V0), 4 screws




Mounting panels, laminated paper, 2 mm

Model	Order no.	Note
B M 0808	96601100	For B 0808..
B M 1008	96602100	For B 1008..
B M 1408	96603100	For B 1408..
B M 1413	96603200	For B 1413..
B M 1808	96604100	For B 1808..
B M 1813	96604200	For B 1813..
B M 2213	96605200	For B 2213..
B M 2330	96608500	For B 2330..
B M 2617	96606300	For B 2617..
B M 2736	96607600	For B 2736..

Scope of delivery: 1 mounting panel

Note: Please order fixing screws order no. 96600000 (for B 08...) and order no. 96600010 (for B 10..., B 14..., B 18..., B 22..., B 26..., B 23... and B 27...) separately.

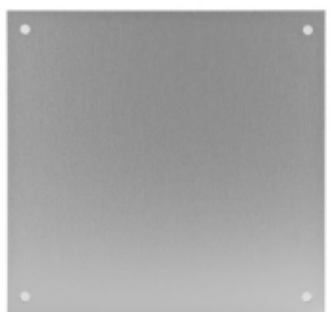

Front panels, 2 mm, natural-coloured anodised aluminium

Model	Order no.	Note
B FP 1008	96702100	For B 1008.., front panel thickness 1.5 mm
B FP 1408	96703100	For B 1408.., front panel thickness 1.5 mm
B FP 1413	96703200	For B 1413.., front panel thickness 1.5 mm
B FP 1808	96704100	For B 1808.., front panel thickness 2.0 mm
B FP 1813	96704200	For B 1813.., front panel thickness 2.0 mm
B FP 2213	96705200	For B 2213.., front panel thickness 2.0 mm
B FP 2330	96708500	For B 2330.., front panel thickness 2.5 mm
B FP 2617	96706300	For B 2617.., front panel thickness 2.5 mm
B FP 2736	96707600	For B 2736.., front panel thickness 2.5 mm

Scope of delivery: 1 front panel

Note: Please order fixing screws order no. 96700000 and distance bolts separately.



Sets of screws

Model	Order no.	Note
B FP-SHR	96700000	A (for fixing front panels)
B M-SHR 0808	96600000	B (for fixing mounting panels B M 0808)
B M-SHR	96600010	C (for fixing mounting panels B M 1008-2736)
B SHR	96300000	D (for optional screwing of enclosures B 0808 - 2617)
B SHR-2	96300002	E (for optional screwing of enclosures B 2330, B 2736)

Scope of delivery: PU = 4 pcs. (exception: B M-SHR 0808, PU = 2 pcs)

Bocube | Accessories

Distance bolts

Model	Order no.	Note
DIBLZ AK 30x5/I1M3/8	96708000	ND = 2,4 - 2,6, for B....04
DIBLZ AK 30x5/I1M3/28	96728000	ND = 2.4 - 2.6, for B....06
DIBLZ AK 30x7/I1M3/26	96726000	ND = 2.4 - 2.6, for B....06 if a mounting plate is used
DIBLZ AK 30x5/I1M3/58	96758000	ND = 2.4 - 2.6, for B....09
DIBLZ AK 30x7/I1M3/56	96756000	ND = 2.4-2.6, for B....09 if a mounting plate is used
DIBLZ AK 30x5/I1M3/88	96788000	ND = 2.4 - 2.6, for B....12
DIBLZ AK 30x7/I1M3/86	96786000	ND = 2.4 - 2.6, for B....12 if a mounting plate is used
DIBLZ AK 30x5/I1M3/76	96776000	ND = 2,4 - 2,6, for B 233012, B 273612
DIBLZ AK 30x7/I1M3/74	96774000	ND = 2,4 - 2,6, for B 233012, B 273612 if a mounting plate is used

Scope of delivery: 4 distance bolts

Note: ND = boss internal diameter



Blanking plugs to determine the hinge side

Model	Order no.	Colour
B VS 7024	96410004	Graphite grey
B VS 7035	96410005	Light grey
B VS 3000	96410000	Flame red

Scope of delivery: Blanking plugs (PC UL 94 V0), PU = 10 pieces



DIN rails DIN EN 60715 TH 15

Model	Order no.	Note
TS 15	22150701	For EM/ET 207-210, EM/ET 225, B 1008..
TS 15	22151101	For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..
TS 15	22151501	For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..
TS 15	22151851	For BCD 160 terminal compartment up, B 2330.. (crosswise)
TS 15	22151901	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..
TS 15	22152301	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
TS 15	22152851	For B 2330..
TS 15	22153451	For B 2736..

Scope of delivery: 1 DIN rail



DIN rails DIN EN 60715 G 32

Model	Order no.	Note
TS 32	22320701	For EM/ET 208-210, EM/ET 225, B 1008..
TS 32	22321101	For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..
TS 32	22321501	For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..
TS 32	22321851	For B 2330.. (crosswise)
TS 32	22321901	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, B 22130.
TS 32	22322301	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
TS 32	22322851	For B 2330..
TS 32	22323451	For B 2736..

Scope of delivery: 1 DIN rail



Bocube | Accessories



DIN rails DIN EN 60715 TH 35

Model	Order no.	Note
TS 35	22350701	For EM/ET 208-210, EM/ET 225, B 1008..
TS 35	22351101	For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..
TS 35	22351501	For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..
TS 35	22351851	For B 2330.. (crosswise)
TS 35	22351901	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..
TS 35	22352851	For B 2330..
TS 35	22352301	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
TS 35	22353451	For B 2736..

Scope of delivery: 1 DIN rail

