



TNC Coaxial Connectors

1. TNC Straight Plug Crimp (Flexible Cable-Crimp Attachment)

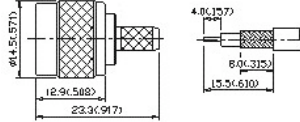


Ordering Code	Applicable Cable RG/U	Finish	Insulation
TNC-50PAN0253B1X	RG 58, 58A, 141A	Center contact: Gold plated Body: Nickel plated	Delrin
TNC-50PAN0253BRX	RG 58, 58A, 141A	Center contact: Gold plated Body: Nickel plated	Teflon

2. TNC Straight Plug Crimp (Flexible Cable-Crimp Attachment)

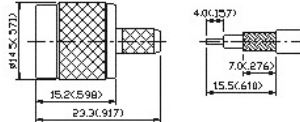


Ordering Code	Applicable Cable RG/U	Finish	Insulation
TNC-50PAN0204B1X	RG 58, 58A, 141A	Center contact: Gold plated Body: Nickel plated	Delrin
TNC-50PAN0204BRX	RG 58, 58A, 141A	Center contact: Gold plated Body: Nickel plated	Teflon
TNC-50PAN0211B1X	RG 59, 62A, 210	Center contact: Gold plated Body: Nickel plated	Delrin
TNC-50PAN0211BRX	RG 59, 62A, 210	Center contact: Gold plated Body: Nickel plated	Teflon
TNC-50PAN0202BRX	RG 174, 188A, 316, 75 Step-down ferrule	Center contact: Gold plated Body: Nickel plated	Teflon
TNC-75PAN0206BRX	RG 179B, 187A, 75 Ohm	Center contact: Gold plated Body: Nickel plated	Teflon

3. TNC Right Angle Plug Crimp (Flexible Cable-Crimp Attachment)

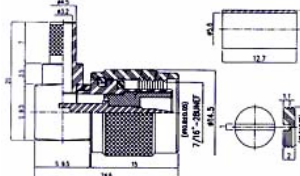


Ordering Code	Applicable Cable RG/U	Finish	Insulation
TNC-50PAN0404BRX	RG 58, 58A, 141A	Center contact: Gold plated Body: Nickel plated	Teflon

4. TNC Straight Bulkhead Jack Crimp (Flexible Cable-Crimp Attachment)

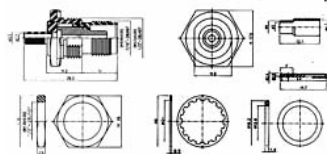


Ordering Code	Applicable Cable RG/U	Finish	Insulation
TNC-50PAN0112BRX	RG 402/U	Center contact: Gold plated Body: Nickel plated	Teflon

9. TNC Straight Bulkhead Jack Receptacle (Bulkhead, Panel Mount Receptacle)

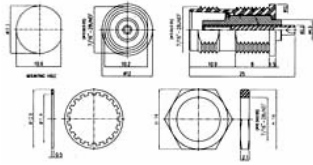


Ordering Code	Finish	Insulation
TNC-50SAN6455BRX	Center contact: Gold plated, Body: Nickel plated	Teflon

10. TNC Straight Bulkhead Jack Receptacle (Bulkhead, Panel Mount Receptacle)

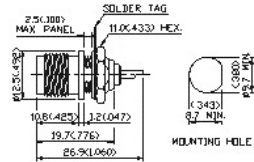


Ordering Code	Finish	Insulation
TNC-50SAN7355B1X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNC-50SAN7355BRX	Center contact: Gold plated, Body: Nickel plated	Teflon

11. TNC Square Flange Jack Receptacle, Exposed Teflon (Bulkhead, Panel PCB Mount Receptacle)

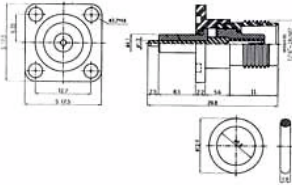


Ordering Code	Finish	Insulation
TNC-50SAN7457BRX	Center contact: Gold plated, Body: Nickel plated	Teflon

 12. TNC Square Flange Jack Receptacle, Solder Pot Contact (Bulkhead, Panel PCB Mount Receptacle)




Ordering Code	Finish	Insulation
TNC-50SAN5255B1X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNC-50SAN5255BRX	Center contact: Gold plated, Body: Nickel plated	Teflon

13. TNC Right Angle PCB Mount Jack Receptacle (Bulkhead, Panel PCB Mount Receptacle)

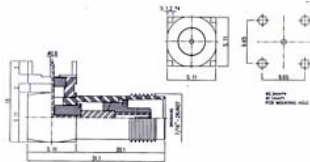


Ordering Code	Finish	Insulation
TNC-50SAN7558BRX	Center contact: Gold plated, Body: Nickel plated	Teflon

14. TNC Jack-Jack (In-Series Adapters)

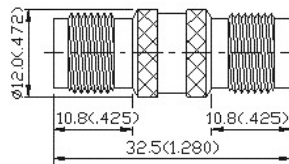


Ordering Code	Finish	Insulation
TNCS-TNCSAN06X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNCS-TNCSAN01X	Center contact: Gold plated, Body: Nickel plated	Teflon

15. TNC Bulkhead Jack-Jack (In-Series Adapters)

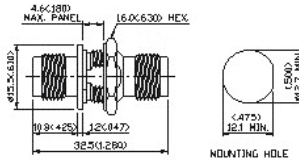


Ordering Code	Finish	Insulation
TNCS-TNCSAN03X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNCS-TNCSAN02X	Center contact: Gold plated, Body: Nickel plated	Teflon

16. TNC Isolated Bulkhead Jack-Jack (In-Series Adapters)

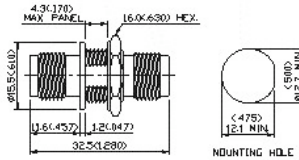

Ordering Code	Finish	Insulation
TNCS-TNCSAN04X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNCS-TNCSAN05X	Center contact: Gold plated, Body: Nickel plated	Teflon

17. TNC Tee Adapter Jack-Plug-Jack (In-Series Adapters)

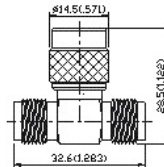

Ordering Code	Finish	Insulation
TNCP-TNCSAN30X	Center contact: Gold plated, Body: Nickel plated	Delrin
TNCP-TNCSAN31X	Center contact: Gold plated, Body: Nickel plated	Teflon

For other plating options contact factory