



Test Clips

SERIES 02

FEATURES

- Rapid, Easy Connections
- Hex Nut for Adjusting Tension
- Choices of Sizes and Styles




Ultra-Miniature

Miniature

Standard Size


DIMENSIONS In Inches (and millimeters)

Ultra Miniature 02-41 and 02-42

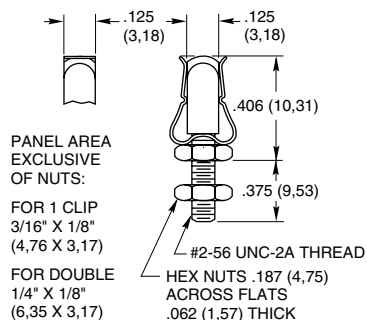


All dimensions are reference.

02-20 Threaded Stud

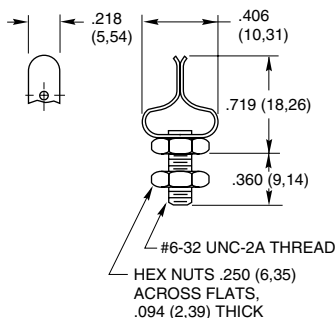


Max. panel thickness .250 (6,35)

Miniature 02-24 Insulated

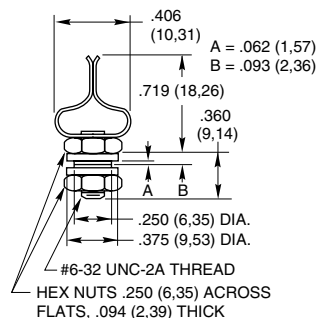


Panel thickness .062 (1,57) to .187 (4,75)

02-21 Standard Banana Plug

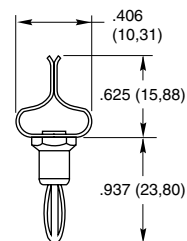


All dimensions are reference.

Standard Size Threadless 02-60

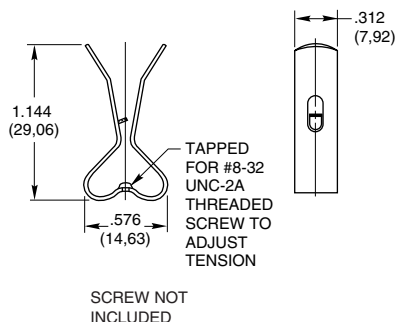


All dimensions are reference.

02-0 Threaded Stud

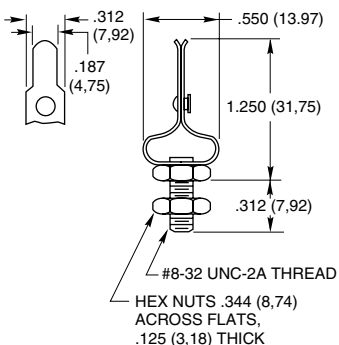


Max. panel thickness .250 (6,35)

Standard Size 02-4 Insulated

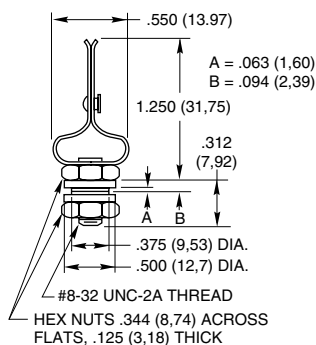

02-1 Standard Banana Plug

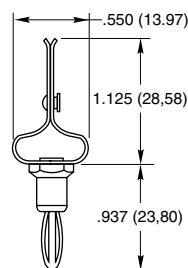

All dimensions are reference.

STANDARD OPTIONS

Standard Size Threaded Stud Clip can be made of Stainless Steel or Inconel X material.
Not available through Distributors.

SPECIFICATIONS

Materials and Finishes

Studs: Nickel-plated steel except for 02-41 and 02-42 which are nickel-plated brass
Rivets and Nuts: Nickel-plated brass
Spring Clips: Nickel-plated brass except for 02-41 and 02-42 which are nickel-plated beryllium copper
Insulators: Thermoset plastic

ORDERING INFORMATION

Order using part numbers shown in dimensions.

Available from your local Grayhill Distributor.
For prices and discounts, contact a local Sales Office, an authorized local Distributor or Grayhill.