


Startseite » Posts » Microphones » Omnidirectional Microphones » F-M-O60-42B

F-M-O60-42B

6mm Condenser Microphone

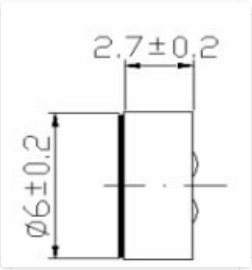

Description

Datasheet

1. SPECIFICATIONS

PARAMETERS	VALUES	UNITS
DIRECTIVITY	Omni-Directional	-
SENSITIVITY (0 dB = 1 V/pa AT 1 KHz)	-42 ± 2	dB
IMPEDANCE	Low Impedance	-
FREQUENCY RANGE	50 - 16,000	Hz
MAX OPERATING VOLTAGE	10	V
STANDARD OPERATION VOLTAGE (Vs)	2	V
RESISTANCE LOADING (RL)	2.2k	Ohm
MAX CURRENT CONSUMPTION	0.5	mA
S/N RATIO	>60	dB
OPERATING TEMPERATURE	-20 to +60	°C
STORAGE TEMPERATURE	-25 to +70	°C

DIGISOUND-Electronic GmbH

Postfach 20 69 - 22810 Norderstedt
Oststrasse 54 - 22844 Norderstedt

Tel. 040 / 52 68 69 - 0
Fax: 040 / 52 68 69 - 13

contact[at]digisound.de
www.digisound.de

Imprint/Privacy Policy | general terms and conditions

