

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0732510450

Status:


Active

Overview:

SMA RF Connectors

Description:

50 Ohms, SMA Plug, Straight, Crimp, RG-174, RG-188, and RG-316 Cable, Brass Body, Gold Plated, with Heat Shrink Tube, Tray

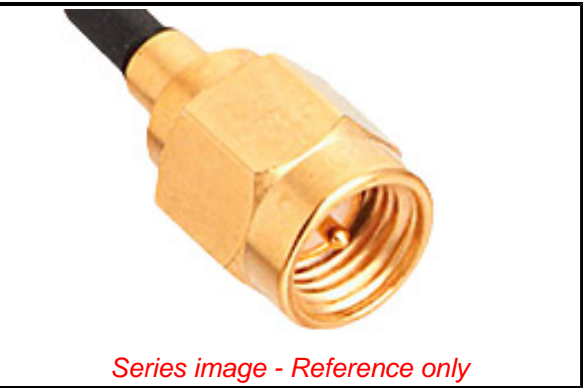

Series image - Reference only

|                                      |  |
|--------------------------------------|--|
| <b>Documents:</b>                    |  |
| <a href="#">3D Model</a>             | <a href="#">Drawing (PDF)</a>                        |
| <a href="#">3D Model (PDF)</a>       | <a href="#">RoHS Certificate of Compliance (PDF)</a> |
| <b>Application tooling part link</b> |  |
| Application Tooling Part Link        | 73415-4550   |
| <b>General</b>                       |  |
| Product Family                       | RF/Coax Connectors                                   |
| Series                               | 73251  |
| Overview                             | SMA RF Connectors                                    |
| Product Name                         | SMA  |
| Style                                | Cable  |
| Type                                 | Subminiature   |
| UPC                                  | 800756108469   |
| Wire/Cable Type                      | LMR-100, RG-174, RG-188, RG-316                      |
| <b>Physical</b>                      |  |
| Gender                               | Plug   |
| Keying to Mating Part                | None   |
| Net Weight                           | 3.323/g  |
| Orientation                          | Straight   |
| PCB Mounting                         | N/A  |
| Packaging Type                       | Tray   |
| Panel Mount                          | No   |
| Panel Mount Method                   | N/A  |
| <b>Electrical</b>                    |  |
| Frequency                            | 18 GHz   |
| Impedance                            | 50Ω  |
| Power / Voltage                      | VOLTAGE: 500 Vrms@Sea Level                          |
| <b>Solder Process Data</b>           |  |
| Lead-freeProcess Capability          | N/A  |
| <b>Material Info</b>                 |  |
| <b>Reference - Drawing Numbers</b>   |  |
| Sales Drawing                        | SD-73251-045   |

|   |                   |
|---|-------------------|
| <b>EU ELV</b>   |                   |
| Not Relevant  |                   |
| <b>EU RoHS</b>  | <b>China RoHS</b> |
| Compliant with Exemption 6(c)                                 |                   |
| <b>REACH SVHC</b>   |                   |
| Contained Per - ED/01/2018 (15 January 2018)                  |                   |
| 2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p              |                   |
| <b>Halogen-Free Status</b>                                    |                   |
| Low-Halogen   |                   |
| For more information, please visit <a href="#">Contact US</a> |                   |
| China ROHS  | 50 Image          |
| ELV   | Not Relevant      |
| RoHS Phthalates   | Not Contained     |

**Search Parts in this Series**  
73251 Series

|   |                  |
|---|------------------|
| <b>Application Tooling   FAQ</b>  |                  |
| Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document. |                  |
| Global  |                  |
| <b>Description</b>  | <b>Product #</b> |
| Crimp Hand Tool with Die Sets   | 734154550        |

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION