


SMPM TO 65 GHz


SMPM Ganged Block:
GPPB

Mates With:
PRFIA

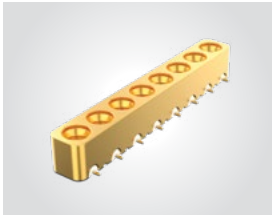

GPPB	GENDER	NO. OF ROWS	NO. OF POSITIONS	PLATING	ST	SM	CHANNEL PITCH
------	--------	-------------	------------------	---------	----	----	---------------

- PF**
= Plug Full Detent
- PS**
= Plug Smooth Bore
- PC**
= Catcher's Mitt
- 1**
- 02, -04, -06, -08, -10**
- EG**
= 50 μ" (1.27 μm) heavy Gold center contact, 10 μ" (0.25 μm) Gold outer body
- 1N**
= 3.56 mm (.140") Pitch

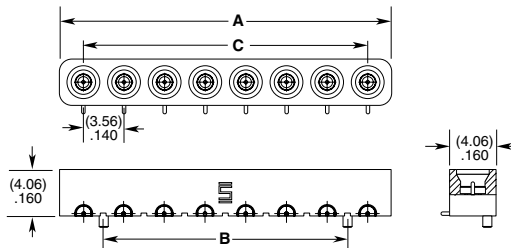

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	N/A	(3.56) .140
-04	(14.73) .580	(7.11) .280	(10.67) .420
-06	(21.84) .860	(14.22) .560	(17.78) .700
-08	(28.96) 1.14	(21.34) .840	(24.89) .980
-10	(36.07) 1.42	(28.45) 1.12	(32.00) 1.26

GPPB-PF-1-08-EG-ST-SM-1N SHOWN

ALSO AVAILABLE

(8.33 mm) .328" Pitch
(5.08 mm) .200" Pitch
Edge Mount termination
Contact: RFGroup@samtec.com

DUAL POSITION SOLDERLESS COMPRESSION MOUNT


SMPM Ganged Block:
GPPC

Mates With:
GC47, GC86, PRFIA



GPPC	GENDER	1	2	PLATING	ORIENTATION	TERMINATION	PACKAGING
------	--------	---	---	---------	-------------	-------------	-----------

- PF**
= Plug Full Detent
- PS**
= Plug Smooth Bore
- EP**
= 50 μ" (1.27 μm) heavy Gold center contact, Passivated outer body
- ST**
= Straight
- CMM**
= Compression Mount
- Leave blank for Individually bagged
- B**
= Bulk Package

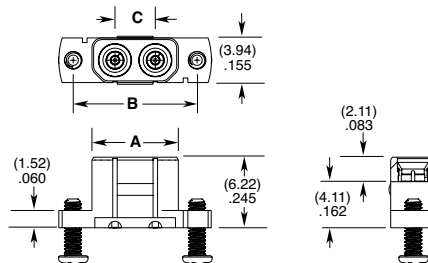

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	(10.92) .430	(3.56) .140

GPPC-PX-1-2-EP-ST-CMM-X SHOWN