




PRODUCT

- ▶ **USB 3.0 Camera**
 - USB 3.0 Camera Module
 - USB 3.0 Box Camera
 - USB 3.0 CCD Camera
 - USB 3.0 Stereo Camera
 - USB 3.0 ZOOM Camera
 - USB 3.0 Accessories
 - CS-Mount Lens
 - M12 Lens
- ▶ **USB 2.0 Camera**
 - VGA USB Camera
 - 720p USB AF Camera
 - 720p USB M8 Camera
 - 2M USB M6 Camera
 - 3M USB Camera
 - 5M USB AF Camera
 - 5M USB Camera
- ▶ **3D Stereo Camera**
 - V024 Stereo Camera
 - OV4689 Stereo Camera
 - OV9281 Stereo Camera**
 - OV9782 Stereo Camera
 - OV7251 Stereo Camera
 - eSP870 3D Depth Camera
- ▶ **CSI-2 MIPI Modules (I-PEX)**
 - CSI-2 MIPI Modules
 - USB 3.0 Tester Kits
 - Nvidia TX1/TX2 Camera Kit**
 - Nvidia TX1/TX2 Carrier Camera**
 - Intel Apollo Camera Kit
 - Xilinx Camera Kit
- ▶ **CMOS Sensor Module**
 - Mobile Module
 - MIPI Camera Module
 - EVA Kit
- ▶ **Serial Camera(Coax) NEW**
 - OV10635 GMSL Module
 - OV10640-490 GMSL Module
 - MLX75411 GMSL Module
 - OV10640 HDR GMSL Camera
 - AR0231 GMSL Camera
- ▶ **IoT WiFi Camera**
 - 720p WiFi Camera(Obsolete)
- ▶ **OEM M38 HD IP Camera Module**
 - HD IP Camera Modules
 - M38 Thermal IP Camera Module
 - CS Lens Mount
 - M12 Lens
 - Accessories
- ▶ **PTZ HD IP Camera Module**
 - 18x Zoom
- ▶ **CMOS Camera Board**
 - Sony
 - Panasonic
 - Aptina
 - Omnivision
 - MIPI Camera
 - HISPI Camera

LI-M38-M034

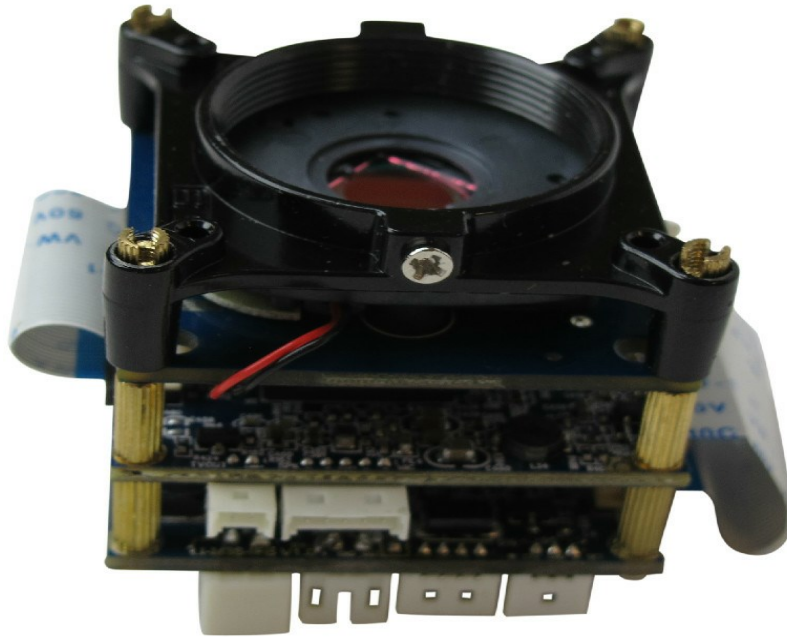

BUY NOW

Overview

Specifications

Download

Model	LI-M38-M034
Image Input	
Sensor Type	Aptina 1/3" CMOS Sensor
Day/Night	Auto Switch (Optional Feature)
e-shoot	1/2 to 1/10,000
Enhance	Auto Enhance
Exposure	Auto Exposure
White Balance	Auto WB
Lens	Fix focus, IRIS support, C/CS mount lens support
Image Process	
Resolution	1290x720, D1, SXVGA
Active Pixels	1280 (H) x 960 (V)
Pixel Size	3.75 μ m x 3.75 μ m
Format	H.264
Frame Rate	H.264/MPEG-4: 30f/s
Network	
Protocols	TCP/IP, HTTP, FTP (client/server), SMTP, DHCP, DNS, NTP, RTP/RTCP
Protocol	ONVIF
Authentication	IEEE802.1X
Interfaces	
Network	10BASE-T/100BASE-TX (RJ-45)
Serial Port	RS-485 (PELCO-D Protocol)
Extension Storage	SD card x1
Alarm In/Out	One channel Input, one channel Output
Audio Input/Output	3.5 MM
Work Environment	
Weight	36 gram
Size	38mm*38mm*26mm
Power Supply	PoE (Optional) or DC12V
Power Consuming	<3w
Temperature	-10°C ~ 60°C
Humidity	10% ~ 80% no condense
Video Management Software	
OS	Microsoft Windows 98/2000/XP/Vista/Win7
Browser	Internet Explorer 6.0 or above
Record Software	Milestone xprotect (3rd software)

- ▶ **Thermal IP Camera**
 - Thermal IP Camera Dev Kit
 - M38 Thermal IP Camera Module
- ▶ **HD Video Camera Modules**
 - VCAM-M034 720p WDR
 - VCAM-AR0130 720p
 - M12 Lens
 - CS-Mount Lens
- ▶ **Development Kit**
 - Leopardboard
 - DM36xEUCDK
 - DM36xECDK

[About Us](#) | [Contact](#) | [Careers](#) | [Partners](#)
Content copyright 20172017. Leopard Imaging Inc. All rights reserved.