

## TECHNICAL DATASHEET

Disclosing the document and its contents to third parties only on the authority of the company  
LEONI Fiber Optics GmbH – All rights reserved. Subject to technical changes and misprints

### HP-ferrule 1000/2,2/K/GR/X/latching (order number: SFER-DS0-19-0020)


#### Product description

The HP- connectors stand for low cost connections technology for polymer optical fibers (POF) and are compatible to the Versatile Link transmitters and receivers.

#### Highlights

- Without dust cap
- Compatible to HFBR 4516
- For POF with outer diameter of 2,2 mm
- Capable for PE, PVC and PA cable sheaths
- Surface preparation by polishing
- Duplex connector


#### photo/ sketch

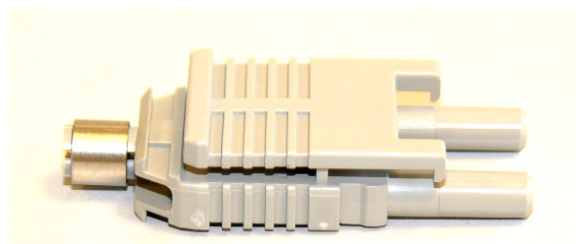

#### Technical description

Typical attenuation	≤ 0,5 dB
Operating temperature	-40 °C to +85 °C
connector retention force	> 50 N
Housing material/ colour	plastics/ gray

#### Technical drawing:

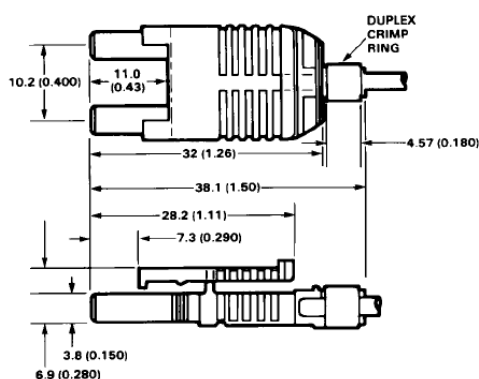

#### Ordering numbers:

HP-ferrule 1000/2,2/K/GR/X/latching	SFER-SS0-19-0020
-------------------------------------	------------------

#### Contact:

**LEONI Fiber Optics GmbH** Mühldamm 6 · D-96524 Neuhaus- Schierschnitz

Tel.: +49 (0)36764/81-100

Fax.: +49 (0)36764/81-110

E-Mail [fiber-optics@leoni.com](mailto:fiber-optics@leoni.com)

[www.leoni-fiber-optics.com](http://www.leoni-fiber-optics.com)

**LEONI Fiber Optics GmbH** Mühldamm 6 · D-96524 Neuhaus- Schierschnitz

Telefon +49 (0)36764/81-100 ·

Fax +49 (0)36764/81-110

E-Mail [fiber-optics@leoni.com](mailto:fiber-optics@leoni.com) ·

[www.leoni-fiber-optics.com](http://www.leoni-fiber-optics.com)

Datenblattbezeichnung

Versionsnummer: 2

Ausgabedatum: 13.10.2009

LFO/NHS/M.Hopf