



P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	27JUL2015	NP	XX
	A1	ECR-15-018715 ADD 114 SPEC.	29DEC2015	NP	XX
	A2	ECR-20-012708 ADD MODEL PG9	22SEP2020	S.C	C.W
	B	ECR-22-132011	25AUG2022	BP	CW

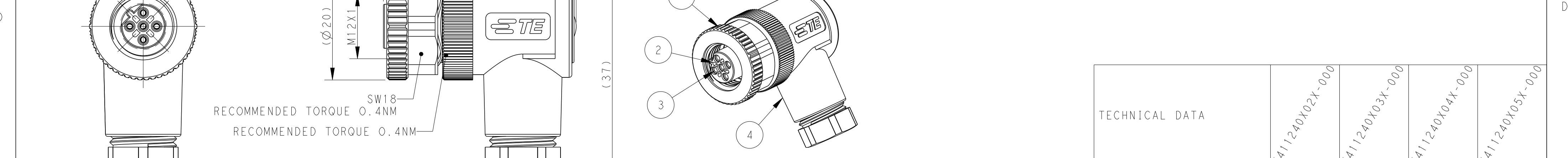

TECHNICAL DATA	T411240X02X-000	T411240X03X-000	T411240X04X-000	T411240X05X-000
RATED VOLTAGE	250V	250V	250V	60V
RATED CURRENT	4A	4A	4A	4A
POLLUTION DEGREE	3	3	3	3
OVERVOLTAGE CATEGORY	II	II	II	II
MATERIAL GROUP	II	II	II	II
CONTACT RESISTANCE	≤10mΩ	≤10mΩ	≤10mΩ	≤10mΩ
INSULATION RESISTANCE	>100MΩ	>100MΩ	>100MΩ	>100MΩ
DEGREE OF PROTECTION	IP67	IP67	IP67	IP67
OPERATION TEMPERATURE	-40~85°C	-40~85°C	-40~85°C	-40~85°C

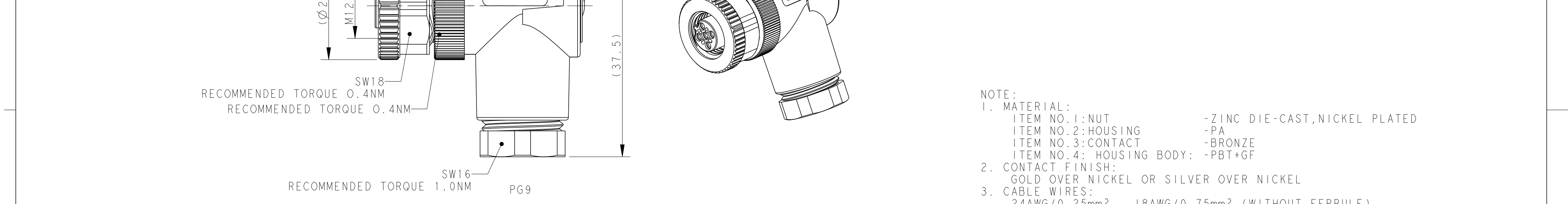

PIN ARRANGEMENT

B-CODE

T411240X02X-000	T411240X03X-000	T411240X04X-000
-----------------	-----------------	-----------------

NOTE:

1. MATERIAL:
ITEM NO.1:NUT -ZINC DIE-CAST,NICKEL PLATED
ITEM NO.2:HOUSING -PA
ITEM NO.3:CONTACT -BRONZE
ITEM NO.4: HOUSING BODY: -PBT+GF


2. CONTACT FINISH:
GOLD OVER NICKEL OR SILVER OVER NICKEL

3. CABLE WIRES:
24AWG/0.25mm²...18AWG/0.75mm² (WITHOUT FERRULE)
26AWG/0.14mm²...20AWG/0.50mm² (WITH FERRULE)

4. ALLDIMENSIONS ARE FOR NOMINAL REFERENCE ONLY UNLESS OTHERWISE STATED

5. PACKAGEING: 1PIECE IN A BAG

6. PN INFORMATION

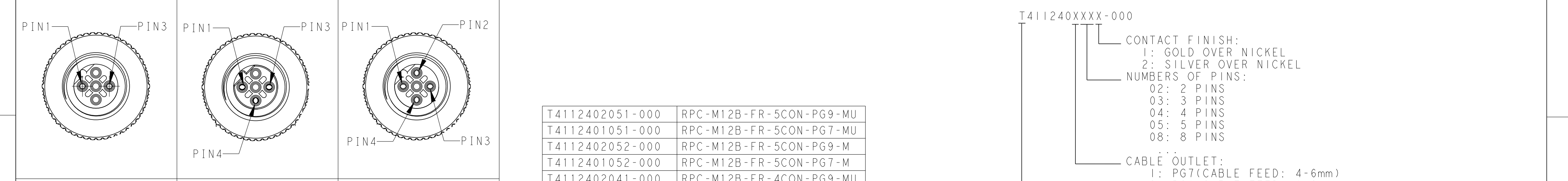

T411240X05X-000			T4112402051-000	RPC-M12B-FR-5CON-PG9-MU
			T4112401051-000	RPC-M12B-FR-5CON-PG7-MU
			T4112402052-000	RPC-M12B-FR-5CON-PG9-M
			T4112401052-000	RPC-M12B-FR-5CON-PG7-M
			T4112402041-000	RPC-M12B-FR-4CON-PG9-MU
			T4112401041-000	RPC-M12B-FR-4CON-PG7-MU
			T4112402042-000	RPC-M12B-FR-4CON-PG9-M
			T4112401042-000	RPC-M12B-FR-4CON-PG7-M
			T4112402031-000	RPC-M12B-FR-3CON-PG9-MU
			T4112401031-000	RPC-M12B-FR-3CON-PG7-MU
			T4112402032-000	RPC-M12B-FR-3CON-PG9-M
			T4112401032-000	RPC-M12B-FR-3CON-PG7-M
			T4112402021-000	RPC-M12B-FR-2CON-PG9-MU
			T4112401021-000	RPC-M12B-FR-2CON-PG7-MU
			T4112402022-000	RPC-M12B-FR-2CON-PG9-M
			T4112401022-000	RPC-M12B-FR-2CON-PG7-M
			TE PN	TYPE

T411240XXXX-000

CONTACT FINISH:
1: GOLD OVER NICKEL
2: SILVER OVER NICKEL

NUMBERS OF PINS:
02: 2 PINS
03: 3 PINS
04: 4 PINS
05: 5 PINS
08: 8 PINS

CABLE OUTLET:
1: PG7(CABLE FEED: 4-6mm)
2: PG9(CABLE FEED: 6-8mm)

BRAND:
T: W/ TE LOGO