


COAXIAL CONNECTOR, PC 3.5, 50 Ohm, Straight cable plug (male)

11_PC35-50-3-4/199_U

Properties

- Particularly well suited for semi-rigid, semi-flex and flexible cable
- Mechanical intermateable with SMA and SK (2.92 mm standard)

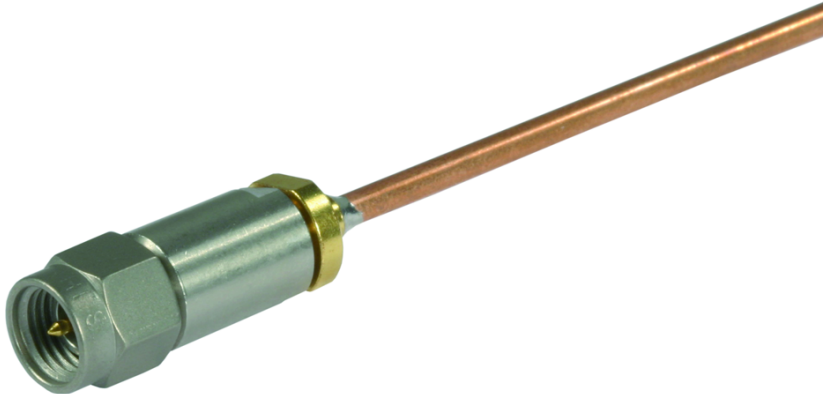

Product configuration		
Interface type	Gender	Standard
PC 3.5	plug	IEC 60169-23

Interface and material data		
Piece parts	Material	Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (without Nickel underplating)
Outer conductor	Stainless Steel	
Body	Stainless Steel	
Insulator	PS (Polystyrene)	
Coupling nut	Stainless Steel	
Gasket	VMQ (Silicone rubber)	

Electrical data	
Impedance	50 Ω
Interface frequency	26.5 GHz

Mechanical data	
Weight	0.0057 kg
Mating cycles	500
Cable entry centre contact	plugged
Cable entry outer contact	soldered

Environmental data	
Operation temperature	-60 °C ... 100°C

COAXIAL CONNECTOR, PC 3.5, 50 Ohm, Straight cable plug (male)
11_PC35-50-3-4/199_U

Ordering Information Table		
Item number	Item description	Packaging type
84009380	11_PC35-50-3-4/199_U	Single
Suitable cables		
Cable group	Y5 - 3 mm / 50 Ohm	
	Y17 - 3 mm / 50 Ohm	
	Y12 - 3 mm / 50 Ohm	
Suitable cables	SUCOFORM_141	
Additional cables	MULTIFLEX_141	
Additional Information		
Only as assembly	No	

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P3539 / Date of publication: 25.11.2023 / uncontrolled copy