

REV. 1  
DCO 16124


COIL: @ +25 °C	
RESISTANCE	27 OHMS ± 10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	1.65 VDC MAX, 0.29 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE & RELEASE 4 MS MAX  
CONTACT STABILIZATION 2.5 MS MAX  
ALL OTHER REQUIREMENTS TO MIL-R-39016 LEVEL M

CUSTOMER DATA SHEET

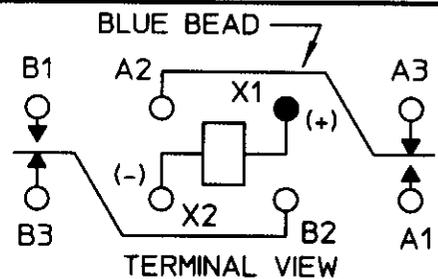

CONTACT RATING: LOW LEVEL TO  
2 AMPS 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. R.B. 3/11/99 CK.Gq/H z/21/00



CUST. QPL  
CUST. NO. M39016/6-139M

TYPE "HFW" RELAY

HFW1201L01M