
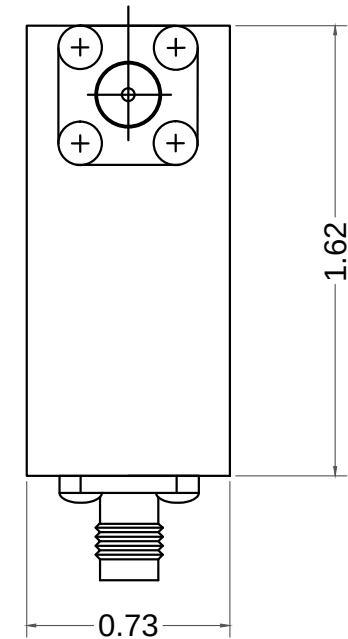


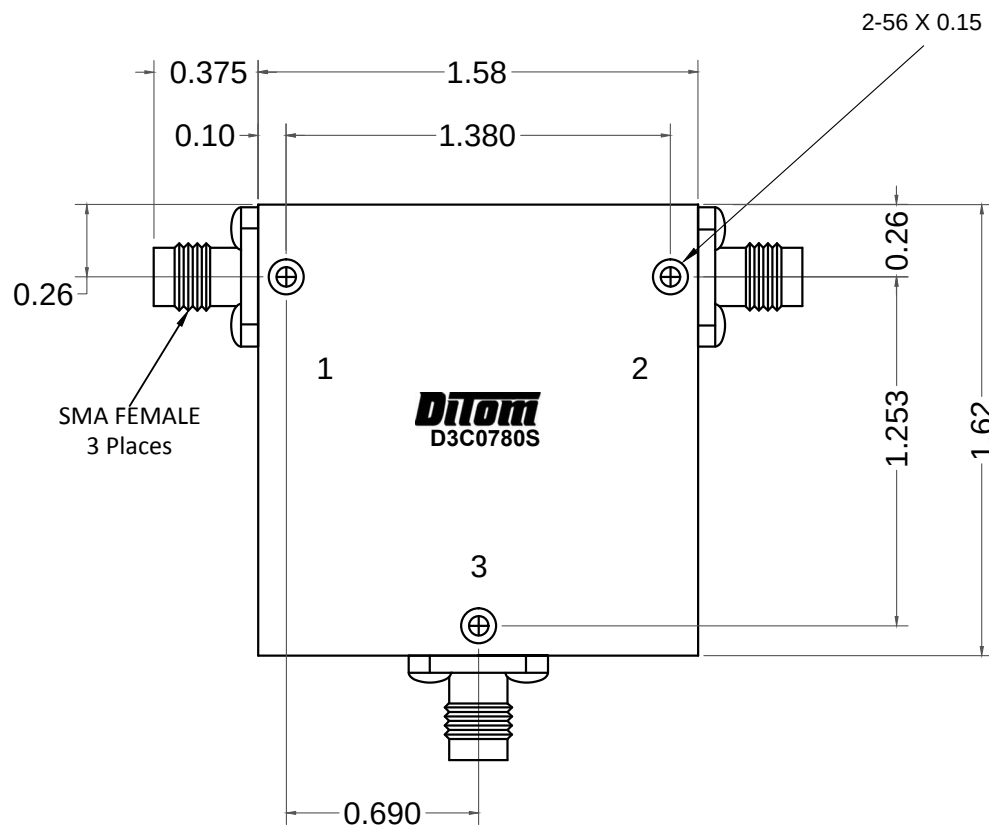

ELECTRICAL SPECIFICATIONS

FREQUENCY RANGE (MHz):	698 - 800
ISOLATION (dB):	20 MIN
INSERTION LOSS (dB):	0.40 MAX
VSWR:	1.25 MAX
POWER: AVG (ALL PORTS):	300W
PEAK:	750W

MECHANICAL SPECIFICATIONS

CONNECTORS:	SMA-FEMALE, STAINLESS STEEL, PASSIVATE
CONTACT PINS:	BERYLLIUM COPPER, GOLD PLATE
OPERATING TEMPERATURE:	-20° to +65°C
WEIGHT (APPROX):	4.50 OUNCES

DIMENSIONS IN INCHES, UNLESS OTHERWISE SPECIFIED		Dilom MICROWAVE INC. Fresno, California, USA	
TOLERANCE	XX±0.03 XXX±0.010	TITLE 698 - 800 MHz Circulator	
SCALE	3:1	MODEL NO D3C0780S	REV