


**BU-31104-@**  
(Insulated, Stackable Banana Plug)

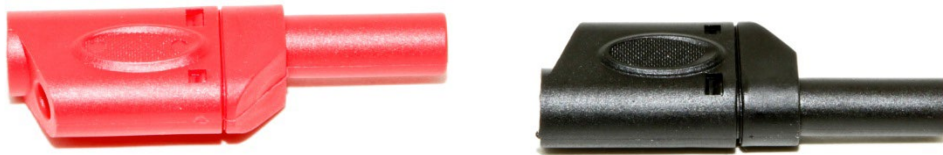

- The BU-31104-@ is a fully insulated, stackable 4mm Banana plug. It can be plugged into any standard 4mm banana jack that accepts shrouded banana plugs. The Jack end will accept shrouded, un-shrouded, or retractable 4mm banana. This part is designed to be soldered to wire from 16-22 AWG and then simply snaps together. The banana plug has a plastic safety tip.
- Overall length of 2.1" (53mm), Width of 0.73" (19mm), and Height of 0.45" (11mm)
- Material:
  - Banana – Nickel plated beryllium copper
  - Insulator – Polypropylene
- Rating:
  - Current – 40 Amps
  - 1,000 V CAT III
- Color: The "@" in the model number indicates color.  
Available colors are: -0 Black, -2 Red
- RoHS 3 Compliant.

### Assembly Instructions



- 1) Thread wire thru offset hole of housing and solder into cross hole in Banana Plug.



- 2) Align the Banana plug into the housing as shown



- 3) Snap together

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524