


WBX 50-2200 MHz for Ettus USRP N210: Rx/Tx (40 MHz)

★☆☆☆☆ (No reviews yet) [Write a Review](#)

SKU: 6002-410-032

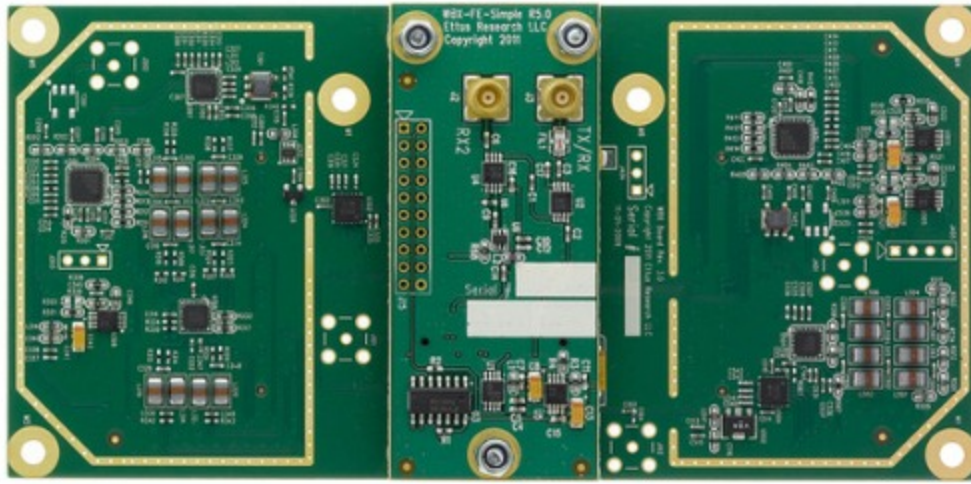

Quantity:

▼ 1 ▲

Add to Cart

Check Distributor Stock

Add to Wish List ▼



Description

Features

What's Included

Support

The WBX is a wide bandwidth transceiver that provides up to 100 mW of output power and a noise figure of 5 dB. The LO's for the receive and transmit chains operate independently, but can be synchronized for MIMO operation. The WBX provides 40 MHz of bandwidth capability and is ideal for applications requiring access to a number of different bands within its range – 50 MHz to 2.2 GHz. Example application areas include land-mobile communications, maritime and aviation band radios; cell phone base stations, PCS and GSM multi-band radios; coherent multi-static radars; wireless sensor networks; transceiver covering 6 amateur bands; broadcast TV; white spaces; public safety; ISM. As of May 22nd 2013, this kit includes two MCX-Bulkhead cables. A second cable is only necessary for applications requiring full duplex operation or the use of both connections on the WBX.

All Ettus products sold through Digilent include Ettus's standard warranty. Find out more on [Ettus.com](#).

Related Products

Customers Also Viewed

Distributor Stock

Hide Distributors

Fetching distributor results

Company

COVID-19 FAQ
About Us
FAQs
Shipping & Returns
Jobs
Legal & Privacy

News

Blog
Newsletter
Events

Affiliations

List of Distributors
Technology Partners

Subscribe to our newsletter

Get the latest updates on new products and upcoming sales

Your email address

Submit

Contact Us

Technical Support Forum
Support Channels

Digilent
1300 NE Henley Ct. Suite 3
Pullman, WA 99163
United States of America