



*Quality Products. Service Excellence.*

## Rack Mount Locking Storage Drawer *RDRW Series*


Up to 145 lbs|66 kg Weight Capacity

### Features



- Constructed of 14 and 16 gauge steel.
- Includes front plastic pull handle locking mechanism.
- Inside of drawer width is 16.12" wide.
- Complete drawer with slides, hardware, lock & two keys.
- Available in 3 depths.
- Rear support brackets included for all depths or can be supported from rear accessory rail.
- Drawer interior smooth white powder paint for high visibility.
- 6-Pack of 10-32 rack screws are included.
- Front face and body finished in black textured powder paint. Inside drawer finished in smooth white powder paint.
- Tested to nearly double the suggested load rating of 145 lbs (66 kg) when mounted to two-pair/4-post rack rails.
  - Rated for 60 lbs (27 kg) when mounted one-pair/2-post rack rails.
- TAA Compliant
- RoHS and REACH compliant.
- Manufactured in North America.

### Gallery

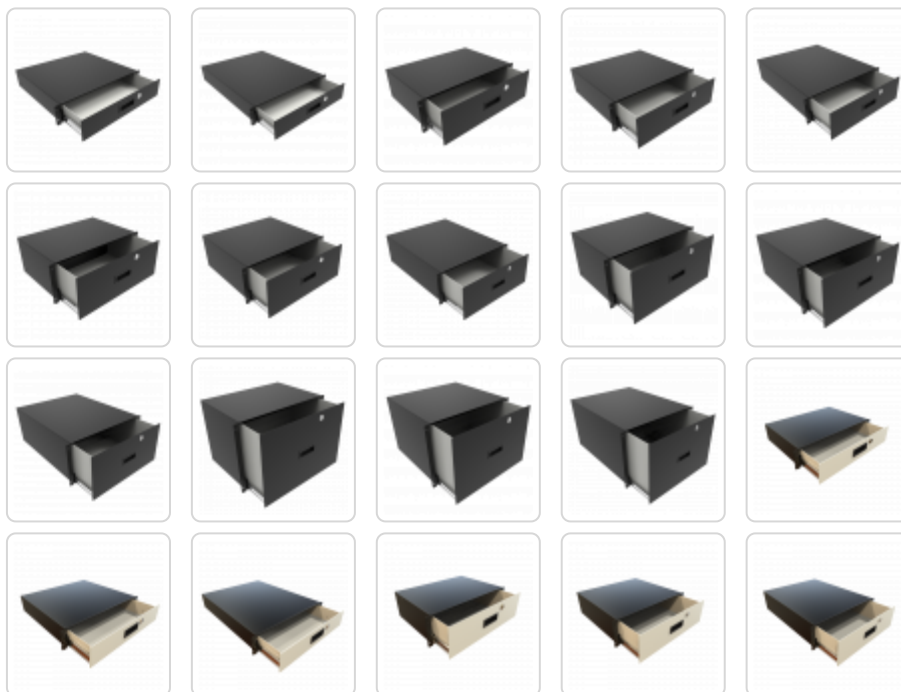



## Accessories

- Mounting Hardware
- Wing Knob Latch



| Part No.<br>Black | Part No.<br>RAL 7035 Light Gray | Overall Dimensions |       |       | Slide<br>Travel | Rack<br>Units | Weight<br>Capacity |
|-------------------|---------------------------------|--------------------|-------|-------|-----------------|---------------|--------------------|
|                   |                                 | Height             | Width | Depth |                 |               |                    |
| RDRW1900312BK1    | RDRW1900312LG1                  | 3.50               | 17.36 | 12.25 | 12.00           | 2U            | 145 lbs (65.8 kg)  |
| RDRW1900512BK1    | RDRW1900512LG1                  | 5.25               | 17.36 | 12.25 | 12.00           | 3U            | 145 lbs (65.8 kg)  |
| RDRW1900712BK1    | RDRW1900712LG1                  | 7.00               | 17.36 | 12.25 | 12.00           | 4U            | 145 lbs (65.8 kg)  |
| -                 | RDRW1900812LG1                  | 8.75               | 17.36 | 12.25 | 12.00           | 5U            | 145 lbs (65.8 kg)  |
| RDRW1901212BK1    | -                               | 12.25              | 17.36 | 12.25 | 12.00           | 7U            | 145 lbs (65.8 kg)  |
| RDRW1900316BK1    | RDRW1900316LG1                  | 3.50               | 17.36 | 16.25 | 16.00           | 2U            | 129 lbs (58.5 kg)  |
| RDRW1900516BK1    | RDRW1900516LG1                  | 5.25               | 17.36 | 16.25 | 16.00           | 3U            | 129 lbs (58.5 kg)  |
| RDRW1900716BK1    | RDRW1900716LG1                  | 7.00               | 17.36 | 16.25 | 16.00           | 4U            | 129 lbs (58.5 kg)  |
| RDRW1900816BK1    | RDRW1900816LG1                  | 8.75               | 17.36 | 16.25 | 16.00           | 5U            | 129 lbs (58.5 kg)  |
| RDRW1901216BK1    | RDRW1901216LG1                  | 12.25              | 17.36 | 16.25 | 16.00           | 7U            | 129 lbs (58.5 kg)  |
| RDRW1900322BK1    | RDRW1900322LG1                  | 3.50               | 17.36 | 22.25 | 22.00           | 2U            | 107 lbs (48.5 kg)  |
| RDRW1900522BK1    | RDRW1900522LG1                  | 5.25               | 17.36 | 22.25 | 22.00           | 3U            | 107 lbs (48.5 kg)  |
| RDRW1900722BK1    | RDRW1900722LG1                  | 7.00               | 17.36 | 22.25 | 22.00           | 4U            | 107 lbs (48.5 kg)  |
| RDRW1900822BK1    | RDRW1900822LG1                  | 8.75               | 17.36 | 22.25 | 22.00           | 5U            | 107 lbs (48.5 kg)  |
| RDRW1901222BK1    | RDRW1901222LG1                  | 12.25              | 17.36 | 22.25 | 22.00           | 7U            | 107 lbs (48.5 kg)  |

© 2020. Hammond Manufacturing Ltd. All rights reserved.