

RJ45 RJ45 jack 10/100 Mbit PoE angl. LV

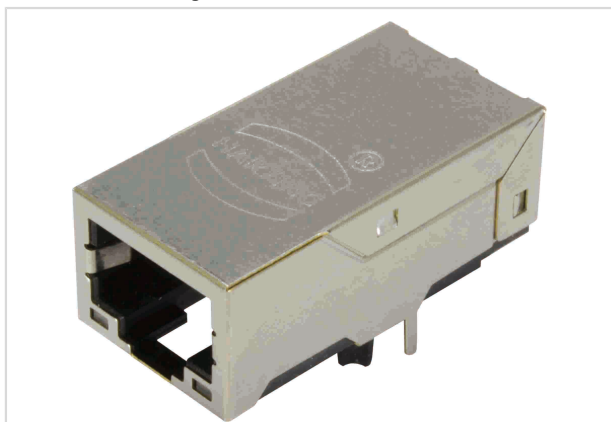


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 551 1151
Specification	RJ45 RJ45 jack 10/100 Mbit PoE angl. LV
HARTING eCatalogue	https://b2b.harting.com/09455511151

Identification

Category	Connectors
Series	HARTING RJ Industrial®
Identification	Magnetics
Element	Female
Specification	RJ45 with integrated transformer Angled

Version

Termination method	Wave soldering termination
Shielding	Fully shielded, 360° shielding contact
Number of contacts	8

Technical characteristics

Rated voltage	60 V
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-40 ... +85 °C
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20

Material properties

RoHS	compliant
ELV status	compliant



Pushing Performance

Material properties

China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Approvals	DNV GL
UL / CSA	UL 1977 DUXR2.E254191 CSA-C22.2 No. 182.4, No. 233-09 DUXR8.E254191

Commercial data

Packaging size	40
Net weight	9.3 g
Country of origin	China
European customs tariff number	85366990
eCl@ss	27460201 PCB connector (board connector)