


YAZ382NTCFX, Cu Compression, 2-Hole, 1/2" Stud, 1-3/4" Spacing, Long Barrel, 500 kcmil H, I, K, 550 kcmil G, H, I, 535 DLO

By Burndy

Catalog # [YAZ382NTCFX](#)

Cu Comp Terminal Flex Cond, Bvl Entry, 2 Hole/W/InspWindow, 535.3 kcmil(1325/#24)DLO, 500 kcmil Flex, 600 V-35 kV, 1/2" Stud, 1.75" Spacing, Lng bbl.

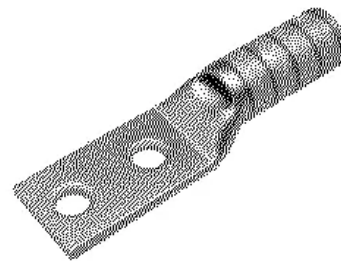

Features

- Barrel is designed with an internal chamfer at the wire entry to ensure smooth insertion of the wire, preventing possible damaging of the strands
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding

Application

Wire Termination

General

Catalog Number	YAZ382NTCFX
Color Code	Pink
Connector Type	LONG BARREL
Die Index	L99
EU RoHS Indicator	Yes
Feature - Barrel Style	Skived
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Plated	Y
Plating Type	Tin
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Long Barrel, Skive
UPC	781810228678
UPC 14 Digit GTIN	00781810228678

Dimensions

Dimension - B Length fraction	2-13/16 in
Dimension - B Length inch	2.81 in
Dimension - Bolt Hole Size inch	0.56 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - Hole Size fraction	3/8

Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm
Dimension - L Length Overall mm	171 mm
Dimension - Length Overall inch	6.72 in
Dimension - Length Side B inch	6.72 in
Dimension - N inch	0.62 in
Dimension - Outside Diameter inch	1.25 in
Dimension - Pad Width inch	1.84 in
Dimension - Strip Length inch	2-3/4
Dimension - Stud Size fraction	3/8
Dimension - Z (inch)	0.65 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper DLO Size	535 KCMIL
Conductor - Copper DLO Size Range	535 kcmil
Conductor - Copper Flex G Size	550 KCMIL
Conductor - Copper Flex G Size Range	550 kcmil
Conductor - Copper Flex H Size	500-550 KCMIL
Conductor - Copper Flex H Size Range	500 / 550 kcmil
Conductor - Copper Flex I Size	500-550 KCMIL
Conductor - Copper Flex I Size Range	500 / 550 kcmil
Conductor - Copper Flex K Size	500 KCMIL
Conductor - Copper Flex K Size Range	500 kcmil
Conductor - Copper Flex M Size	500 kcmil

Conductor - Copper Flex M Size Range	500 kcmil
Conductor - Copper Str Size	500-550 KCMIL
Conductor - Copper Str Size Range	500 / 550 kcmil
Conductor - Material	COPPER
Conductor Size	500-550 KCMIL
Conductor Type	FLEX
Wire Size	500-550 KCMIL

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	1800

Product Assets

- Catalogs - BURNDY Master Catalog - Section C - Compression Connections
- Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog
- Customer Notices - Prop 65 Notice
- Installation Manuals - Copper Flex Long Terminals Tooling and Installation Instructions
- Installation Manuals - Medium & Large HYDENT Copper & Aluminum Terminal Crimp Instructions with 750 Series 12-Ton Tool
- Interactive Catalog - BURNDY Full-Line Digital Catalog
- Sales Drawings - se212273-42
- Specifications - YAZ382NTCFX
- Video - HYDENT Compression Terminal Overview Video

