


Part Number : [685070821](#)

Product Description : 1.02mm Tab, Wire-to-Wire Housing, Male, 8 Circuits, Clip Type

Series Number : 68507

Status : Obsolete

Product Category : Connector Housings

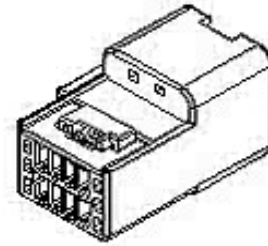

Documents and Resources

Specifications

[PK-68507-002-001.pdf](#)

[PS-104000-001-013.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Contained per D(2021)4569-DC (8 July 2021)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Obsolete
Category	Connector Housings
Series	68507
Description	1.02mm Tab, Wire-to-Wire Housing, Male, 8 Circuits, Clip Type
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	756054305744

Physical

Circuits (maximum)	8
Color - Resin	Black, Yellow
Gender	Plug
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	6.401/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +80°C

Mates With / Use With

Use with Part(s)

Description	Part Number
1.01mm Tab-Type Female Crimp Terminals	<u>50654</u>

Obsolete