


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/16 in.
Stud Size	1/4 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLACK
Panduit Die Index No. on Barrel	P45
Alternate Industry Die Index No. () on Barrel	(13)



CERTIFIED LISTED
Wire Connector

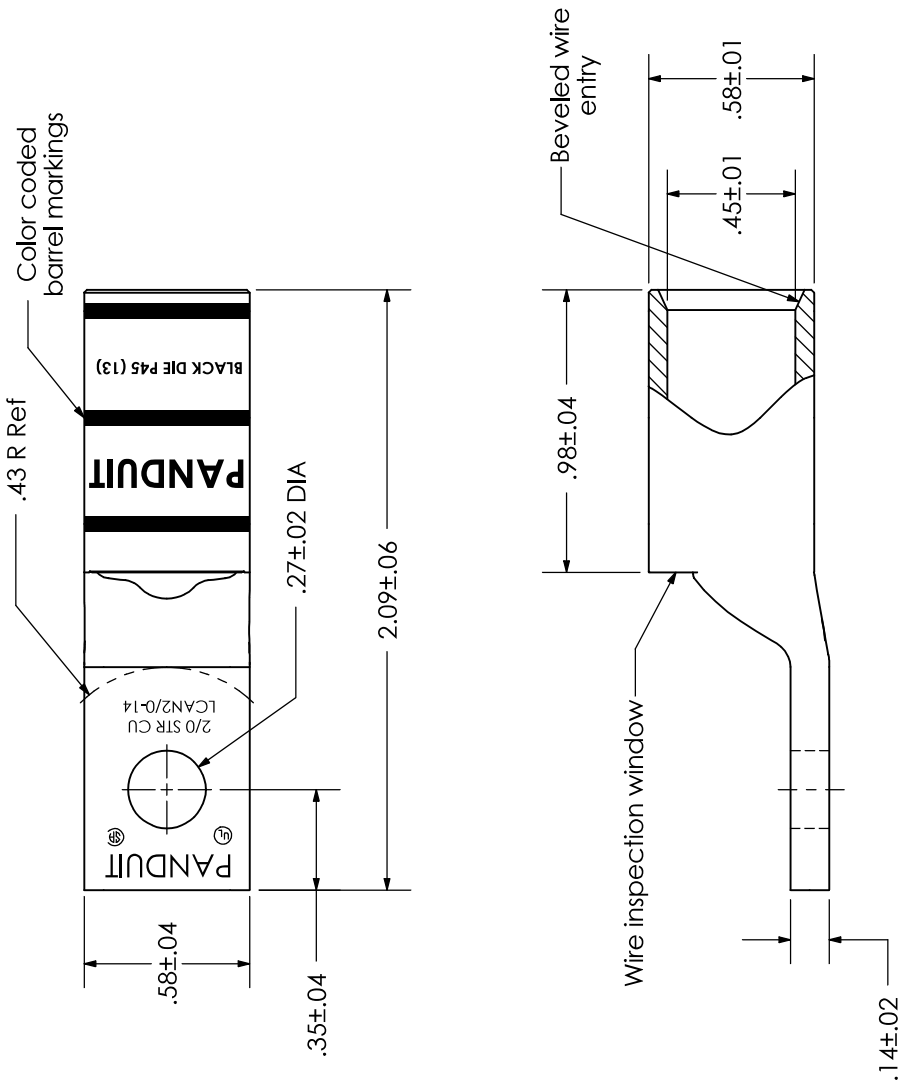

								PANDUIT CORP. TINLEY PARK, ILLINOIS	
								LCAN2/0-14-X	
								Copper Lug - One-Hole, Narrow Tongue, Standard Barrel	
01	11/08	DRL	DRL	TONGUE THICKNESS WAS .13±.01					
REV	DATE	BY	CHK	DESCRIPTION			ECN	SCALE	DRAWING NO / CAD FILE
								N/A	LCAN2_0-14-CUST