



Pushing Performance
Since 1945

Han-Mod_M_USB-C_F_C.1_Coupler

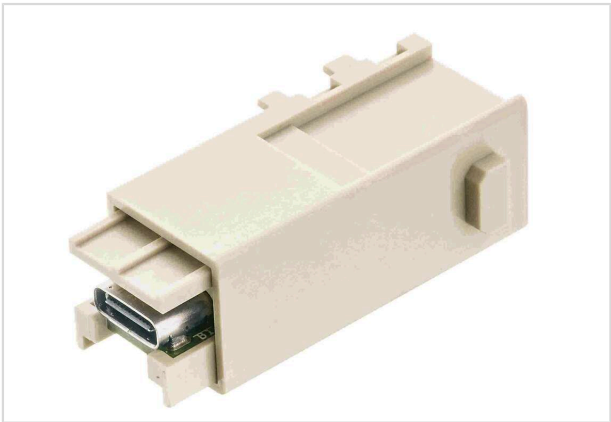


Image is for illustration purposes only. Please refer to product description.

Part number	97 00 000 0146
Specification	Han-Mod_M_USB-C_F_C.1_Coupler
HARTING eCatalogue	https://harting.com/97000000146

Identification

Category	Modules
Series	Han-Modular®
Specification	USB Type C
Type of module	Han® Domino USB-C Cube
Size of the module	Domino module
Description of the module	Gender changer for patch cable Small tab
Features	supports USB Power Delivery (USB-PD)

Version

Gender	Female
Connection type	Type C jack - type C jack
Number of contacts	24

Technical characteristics

Rated current	5 A
Rated voltage	20 V
Limiting temperature	-40 ... +85 °C
Mating cycles	≥500
Vibration resistance	Category 1B acc. to IEC 61373
Shock resistance	Category 1B acc. to IEC 61373



Pushing Performance
Since 1945

Material properties

Material (insert)	Polycarbonate (PC)
	Polyamide (PA)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	1
Net weight	4.7 g
Country of origin	Romania
European customs tariff number	85366990
eCl@ss	27440218 Module for industrial connectors (data)
ETIM	EC000438
UNSPSC 24.0	39121552