


Specification Sheet

Part Number: 151-00623

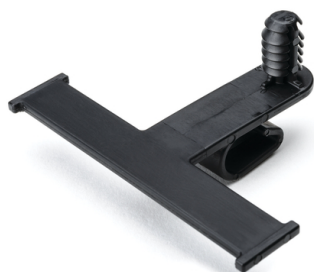

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Article Number 151-00623

Type SOCHFT6

Color Black (BK)

Quantity Per pack

Product Description Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.

Short Description Standoff Bundling Clip, 2.2" Long, 0.03 - 0.22" Panel Thickness, PA66HIRHSUV, Black, 1500/box

Global Part Name

SOCHFT6-PA66HIRHSUV-BK

Length L (Imperial)

2.2

Length L (Metric)

56.0

Offset Length (Imperial)

1.28

Offset Length (Metric)

32.5

Fixation Method

Fir Tree

Bundle Diameter Min (Imperial)

0.28

Bundle Diameter Min (Metric)

7.0

Bundle Diameter Max (Imperial)

0.28

Bundle Diameter Max (Metric)

7.0

Height H (Imperial)

0.9

Height H (Metric)

22.5

Panel Thickness Min (Imperial)

0.03

Panel Thickness Max (Imperial)

0.22

Panel Thickness Min (Metric)

0.7

Panel Thickness Max (Metric)

5.5

Mounting Hole Diameter D (Imperial)	0.25 - 0.27 "
Mounting Hole Diameter D (Metric)	6.3 - 6.9 mm
Mounting Hole Diameter D Min (Imperial)	0.25
Mounting Hole Diameter D Max (Imperial)	0.27
Mounting Hole Diameter D Max (Metric)	7.0
Material	Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)
Material Shortcut	PA66HIRHSUV
Flammability	UL 94 HB
UV Resistant (Yes/No)	Yes
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Operating Temperature intermittant, 1000 hours	+320°F (+160°C)
Operating Temperature intermittant, 5000 hours	+257°F (+125°C)
Operating Temperature intermittant, 500 hours	+329°F (+165°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes

Package Quantity (Imperial)	1500
Package Quantity (Metric)	1500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)