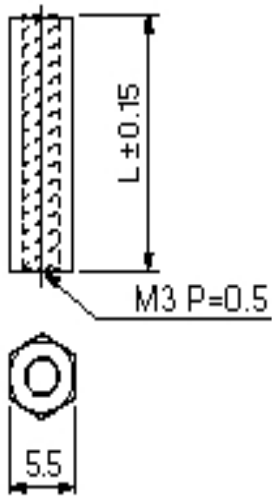


MP, MQ Series

all categories > through hole technology > spacer (resin) > circular threaded spacer (M3), MP=female/female, MQ=male/female


**Circular threaded spacer (M3), MP=female/female, MQ=male/female**


- Color...Milky white
- Finish...Metal part.Nickel plating
- Material...
  - Body part..Acetal copolymer (UL94HB)
  - Metal part..Brass
- Temperature Range (degrees Celsius)...-40 to +85

- [Save To Favorites](#)
- [Download Catalog](#)

[Ask a Question](#)
[Pre-Production Quote Request](#)
[Request Sample](#)
[ADD TO CART](#)

>> request quote / information | >> download specs

NO	L (mm)
MP-4	4
MP-5	5
MP-6	6
MP-7	7
MP-7.5	7.5
MP-8	8
MP-9	9
MP-10	10
MP-11	11
MP-12	12
MP-12.5	12.5
MP-13	13
MP-14	14
MP-15	15
MP-16	16
MP-17	17
MP-17.5	17.5
MP-18	18
MP-19	19
MP-20	20
MP-25	25
MP-30	30
MQ-7	7
MQ-8	8
MQ-9	9
MQ-10	10
MQ-11	11
MQ-12	12
MQ-13	13
MQ-14	14
MQ-15	15
MQ-16	16
MQ-17	17
MQ-18	18
MQ-19	19
MQ-20	20
MQ-25	25
MQ-30	30

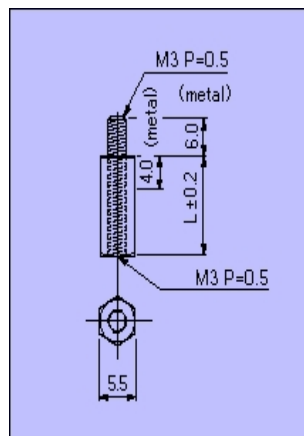

[Pre-Production Quote Request](#)