


GAR6426, Mech Grounding Connector, Cable to Rod or Pipe

By Burndy
Catalog # [GAR6426](#)

Mechanical Grounding Connector, Cable to Rod or Pipe, 4 AWG (Sol)-2/0 AWG (Str), 3/8" Pipe, 5/8"-3/4" Rod, #5-#6 Rebar

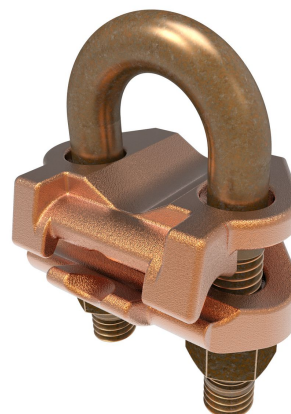

Features

- Wire to Rebar
- Fence Post Grounding Connector
- Wire to Pipe
- One-wrench installation
- Rated for Direct Burial in earth or concrete
- UL467 Listed for US and Canadian Markets
- Select connectors qualified to IEEE-837-2014

Application

For Joining A Range Of Cable, Parallel Or At Right Angles To Rod Or Tube, Direct Burial Cable, Fence Post

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	<ul style="list-style-type: none"> • 5 • 6
Conductor - Pipe or Round Tube Size	3/8 in
Conductor - Rebar Size Range	5 -6
Conductor - Rod Size Range	5/8 in-3/4 in
Conductor - Copper Str Size	<ul style="list-style-type: none"> • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG

Conductor - Rod Size	0.625in - 0.75in
Conductor - Copper Solid Size	<ul style="list-style-type: none"> • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG
Conductor - Copper Solid Size Range	4 AWG-2/0 AWG
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Size • CU C Str-Size • CU Tube Std-Size • Rod-Size
Conductor - Copper Str Size Range	5 AWG - 2/0 AWG
Conductor - Copper Tube Std Size Range	3/8 IPS IPS
Conductor - Copper Tube Std Size	3/8 IPS IPS

Dimensions

Package Height	0.000 in
Dimension - Height mm	73.2 mm
Dimension - Height inch	2.88 in
Dimension - Height fraction	2-7/8 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	40 mm
Dimension - Outside Diameter inch	0.68 in
Dimension - Width fraction	2-1/8 in
Dimension - Width mm	52 mm
Dimension - Width inch	2.06 in
Dimension - B Length inch	1.50 in
Dimension - Length Overall inch	1.56 in

Force Related

Installation Torque Recommended in-lb	240 lb-in
---------------------------------------	-----------

General

Material - Hardware	DURIUM™ Silicon Bronze
---------------------	------------------------

Plated	N
Sub Brand	MECHANICAL CONNECTOR
UPC	781810238202
Type	GAR
U Bolt Type	269
Material	Copper Alloy
Plating Type	Bright Dipped
UPC 12 Digit	781810238202
UPC 14 Digit GTIN	00781810238202

Logistics

Minimum Pack Quantity	1
Pallet Quantity	2400
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)



A Hubbell brand

© 2026 Hubbell Incorporated. All rights reserved
BRDY-GAR6426-SPEC-EN | REV 5/2026