


## Data Sheet | Item Number: 734-426

Strain relief plate; for female and male connectors; 1 part; Pin spacing 3.5 mm; light gray

<https://www.wago.com/734-426>

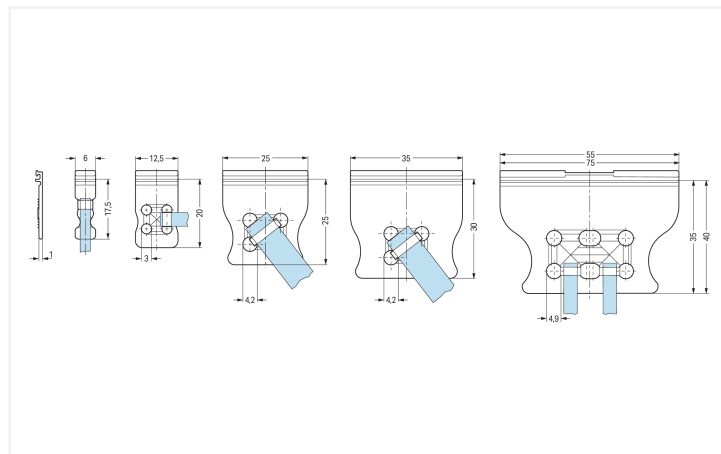

Color: ■ light gray

Dimensions in mm

The arrangement of the attachments for cable ties allows single conductors or multi-core cables to be secured in different ways. The width of the cable ties must correspond to the hole dimensions of the strain relief plates shown above.

### Physical data

Width	55 mm / 2.165 inches
Height	1.87 mm / 0.074 inches
Depth	37 mm / 1.457 inches

### Mechanical data

Mounting type	Insert
Suitable	for standard male and female connectors (2.5 mm; 3.5 mm; 5 mm; 7.5 mm pin spacing)

### Material data

Note (material data)	<a href="#">Information on material specifications can be found here</a>
Color	light gray
Fire load	0.073 MJ
Weight	2.7 g

### Commercial data

Product Group	3 (Multi Conn. System)
PU (SPU)	50 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454163143
Customs tariff number	85389099990

Product Classification	
UNSPSC	39121702
eCl@ss 10.0	27-44-04-92
eCl@ss 9.0	27-44-04-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

### Approvals / Certificates

#### Approvals for marine applications



Approval	Standard	Certificate Name
LR Lloyds Register	IEC 61984	96/20035 (E5)

### Downloads

#### Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 734-426	<a href="#">↓</a>

### Documentation

Additional Information			
Technical Section	03.04.2019	pdf 2027.26 KB	<a href="#">↓</a>


### CAD/CAE-Data

CAD data	
2D/3D Models 734-426	<a href="#">↓</a>

CAE data	
ZUKEN Portal 734-426	<a href="#">↓</a>

## Installation Notes

### Installation

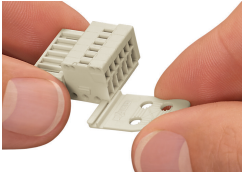


Strain relief plates for factory or in-the-field assembly

### Application



Strain relief plate, for factory assembly  
1-conductor female connector, 2.5 mm pin spacing, light gray,  
12-pole, with strain relief plate  
733-112/034-000

### Application

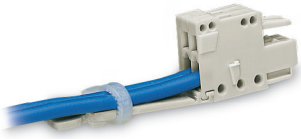

Strain relief plate, for factory assembly  
1-conductor female connector, 2.5 mm pin spacing, light gray,  
2-pole, with strain relief plate  
(733-102/032-000)