




**Part Number :** [1510760012](#)

**Product Description :** 11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 2 Circuits

**Series Number :** 151076

**Status :** Active

**Product Category :** Connector Accessories

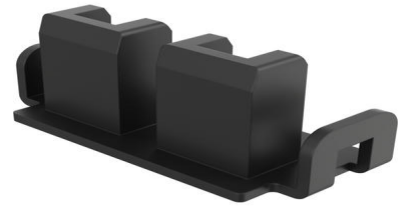

---

## Documents and Resources

### Drawings

[1510760012\\_sd.pdf](#)

[PK-151076-0001-001.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


### Specifications

[PS-151053-0000-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

## Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Connector Accessories
Series	151076
Description	11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 2 Circuits
Component Type	Terminal Position Assurance (TPA)
Product Name	EXTreme Guardian
UPC	889056209328

### Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Polybutylene Terephthalate (PBT)
Net Weight	1.075/g
Number of Rows	1
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

### Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

## Mates With / Use With

### Use with Part(s)

Description	Part Number
11.00mm Pitch EXTreme Guardian Power Receptacle Assembly, PBT, 2 Circuits	<u>1510340012</u>

---

This document was generated on May 26, 2026