


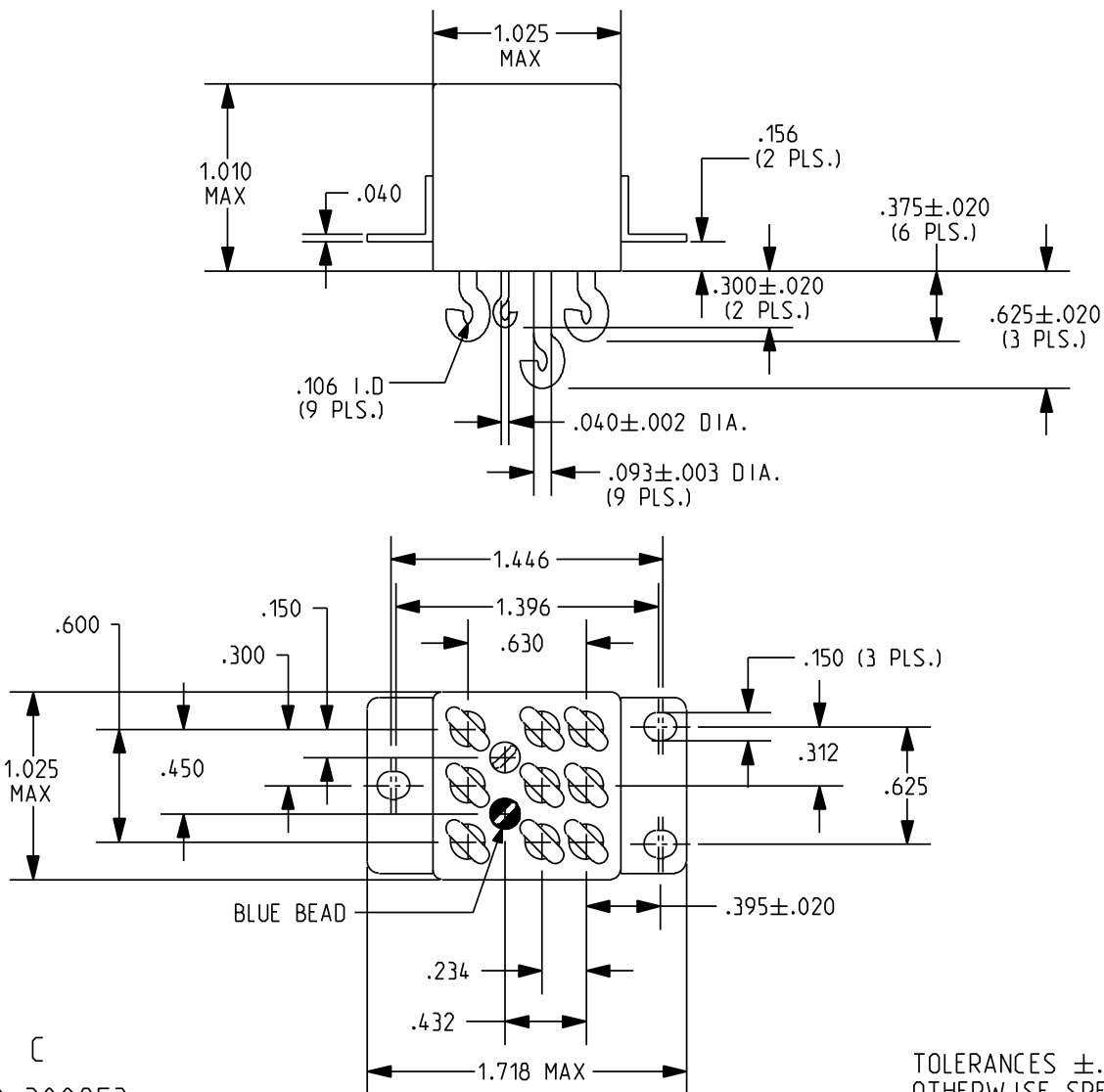

REV. C
DCO 300853

TOLERANCES $\pm .010$ " - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C
RESISTANCE _____ CURRENT: 30mA MAX.
NOMINAL VOLTAGE _____ 115 VAC - 50/400Hz
MUST OPERATE _____ 70.0 VAC MAX., 50/400Hz
MUST RELEASE _____ 25.0 VAC MAX., 8.0 VAC MIN., 50/400 Hz


ENVIRONMENT:
VIBRATION _____ 33 Hz TO _____ 3000 Hz @ _____ 30 g's
SHOCK _____ 200 g's _____ 6 MS. DURATION
TEMPERATURE _____ -70 °C TO _____ +125 °C

NOTES: OPERATE TIME 20 MS MAX.
RELEASE TIME 50 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUST. _____ CATALOG
CUST. NO. _____ REV. N/A

TE NUMBER
6-1617753-7

CUSTOMER DATA SHEET

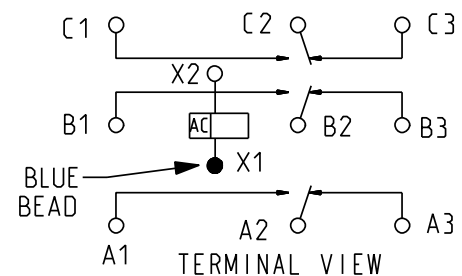

CONTACT RATING:
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 10APR2008 CK. J.M.B. 5/14/08

Tyco Electronics

©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CII PART NUMBER

FCA-325-CY9