

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201030005

Status:


Active

Overview:

PROFIBUS Solutions

Description:

PROFIBUS Attachable D-Sub Connector without Diagnostics LEDs, 90° Angle

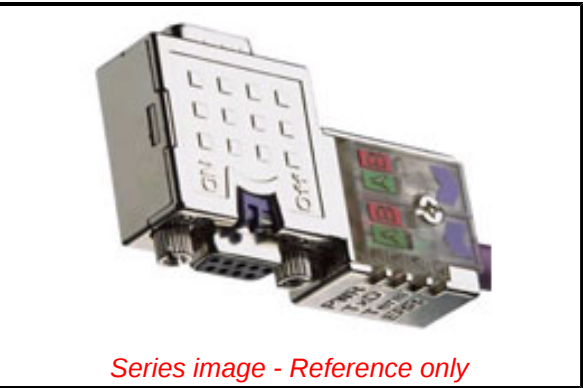

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Field Attachable / Accessories
Series	120103
IP Rating	IP67
Material - Contact	N/A
Overview	PROFIBUS Solutions
Product Name	D-Sub, PROFIBUS
Type	Field Attachable Connector
UPC	78678854818
Physical	
Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	Yes
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	Die-Cast Zinc
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Net Weight	80.000/g
Orientation	90° Angle
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	30V
Material Info	
Engineering Number	PA9S01-42
Reference - Drawing Numbers	
Sales Drawing	SD-120103-004

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120103 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION