


HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

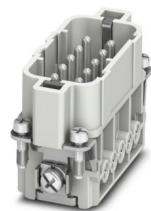

Contact insert, number of positions: 10+PE, size: D15, number of connections per position: 1, Pin, Screw connection, 250 V, 16 A, 0.5 mm² ... 2.5 mm²

Your advantages

- Can be coded with plastic coding profile (order number 1410916)
- For a test pin 2 mm in diameter

Commercial data

Item number	1585294
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF61
Product key	BF7ABB
Catalog page	Page 519 (C-2-2019)
GTIN	4046356285025
Weight per piece (including packing)	46.1 g
Weight per piece (excluding packing)	42.35 g
Customs tariff number	85366990
Country of origin	CN

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



Technical data

Notes

General	for flexible conductors with or without ferrules
General	Connectors may be operated only when there is no load/voltage.
General	for housing HC-D15

Mounting

Assembly instructions	To ensure correct use, installation in housing with IP54 protection or better is required
	for plastic coding profiles: 4 pcs.


Product properties

Type	D15
Product type	Contact insert with a fixed no. of positions
Number of positions	10
Connection profile	10+PE
Contact numbering	1 - 10
Number of connections per position	1
Contact material type	turned
Series	HC-A
Screwdriver blade	0.5 x 3.5 mm

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Dimensions

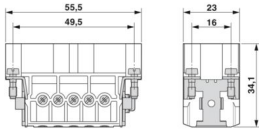Dimensional drawing	
Width	23 mm
Height	34.1 mm
Length	55.5 mm
Drill hole distance, horizontal	49.5 mm
Drill hole distance, vertical	16 mm

Mechanical characteristics

Contact diameter	2.5 mm
------------------	--------

Connection data

Connection technology	
-----------------------	--

HC-A10-I-UT-M - Contact insert



1585294

<https://www.phoenixcontact.com/us/products/1585294>

Connection technology	Screw connection
Number of connections per position	1
Connection in acc. with standard	IEC / EN

Conductor connection

Conductor cross section	0.5 mm ² ... 2.5 mm ²
Connection cross section AWG	20 ... 14
Tightening torque	0.7 Nm ... 1 Nm (PE connection)
	0.5 Nm ... 0.8 Nm (Mounting screws for mounting in the HEAVYCON housing)
	0.5 Nm
Stripping length of the individual wire	7 mm

Electrical properties

Rated voltage (III/3)	250 V
Rated surge voltage	4 kV
Rated current	16 A
SCCR	5 kA (UL 2237)

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

Material specifications

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Ag
Contact carrier material	PC
Standards/regulations	PC: Fire protection in rail vehicles - requirement sets R22, R23, and R24 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (including heating up of contacts)
---------------------------------	--

Standards and regulations

Testing

Standards/regulations	PC: Fire protection in rail vehicles - requirement sets R22, R23, and R24 acc. to DIN EN 45545-2 (Risk level HL1 - HL3)
-----------------------	---

HC-A10-I-UT-M - Contact insert


1585294

<https://www.phoenixcontact.com/us/products/1585294>



Drawings

Dimensional drawing

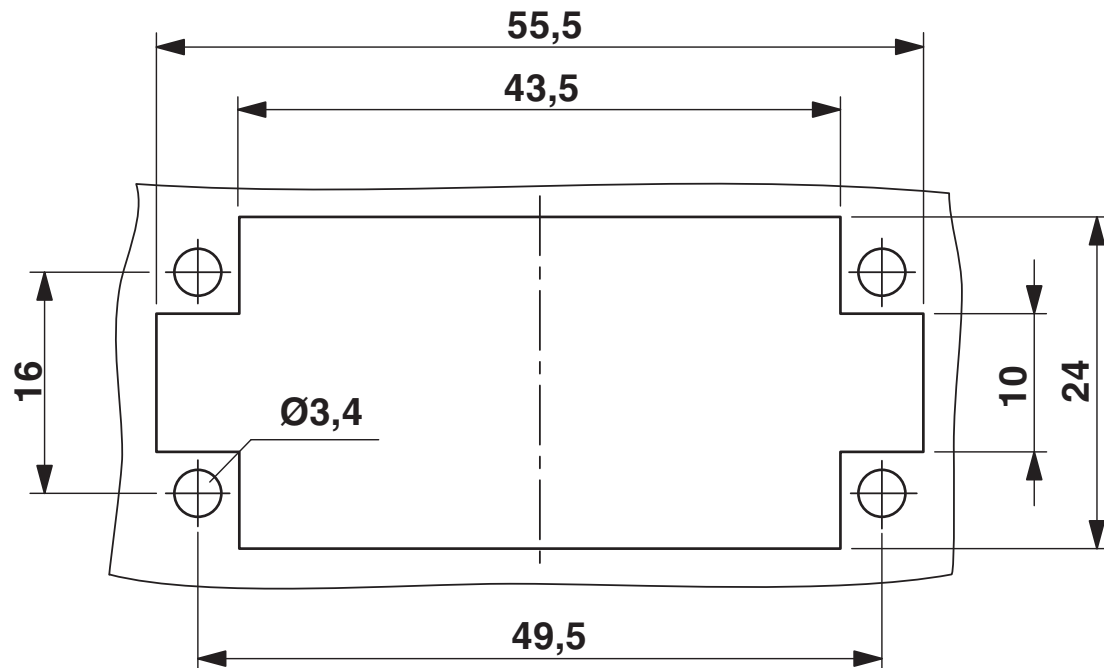

Mounting cutout when used without housing


HC-A10-I-UT-M - Contact insert



1585294


<https://www.phoenixcontact.com/us/products/1585294>

Schematic diagram

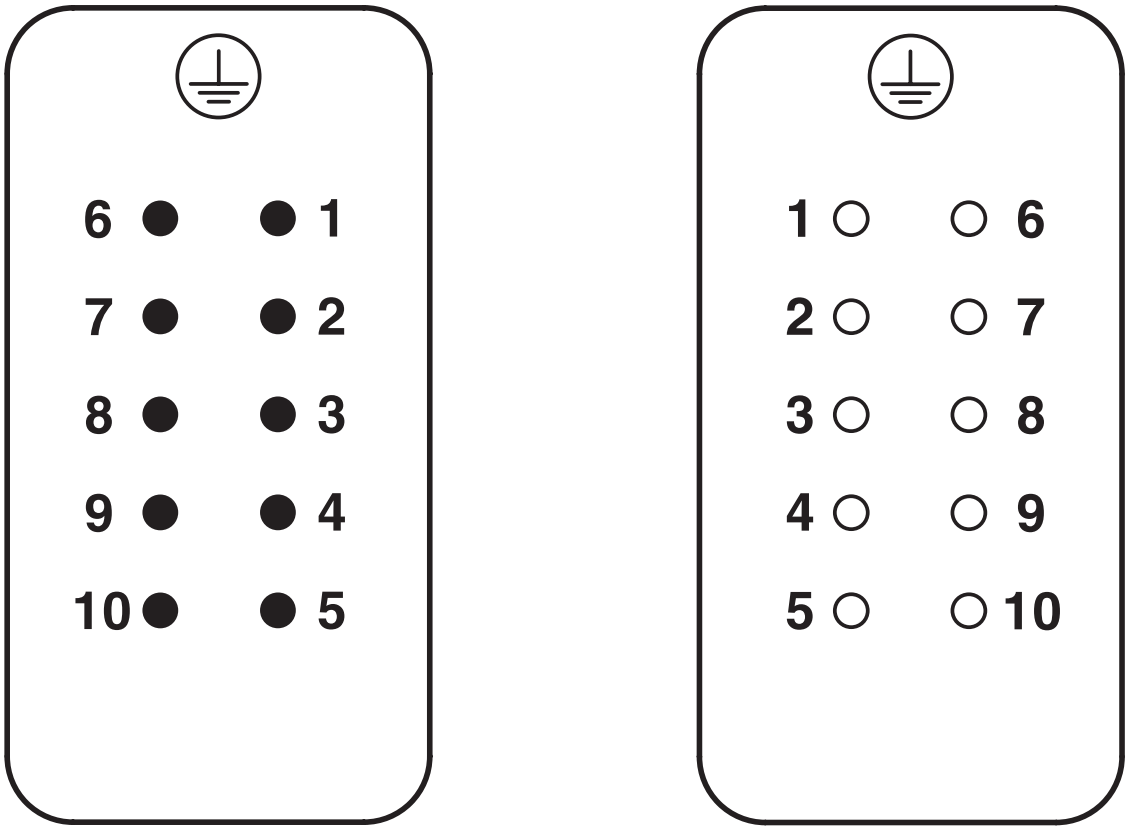

Pin assignment, connection side, pin left, socket right

Dimensional drawing

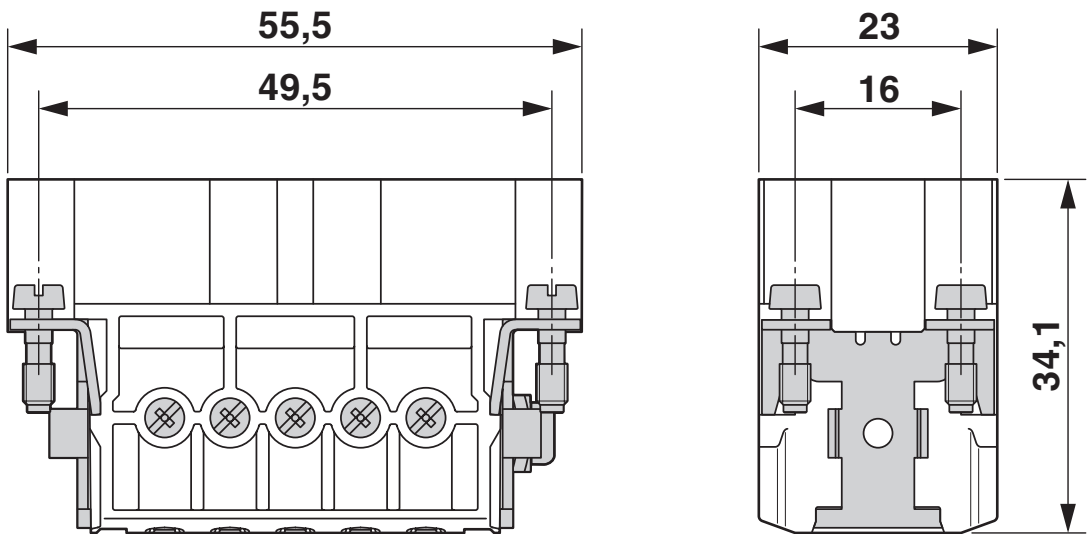


Male insert

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>

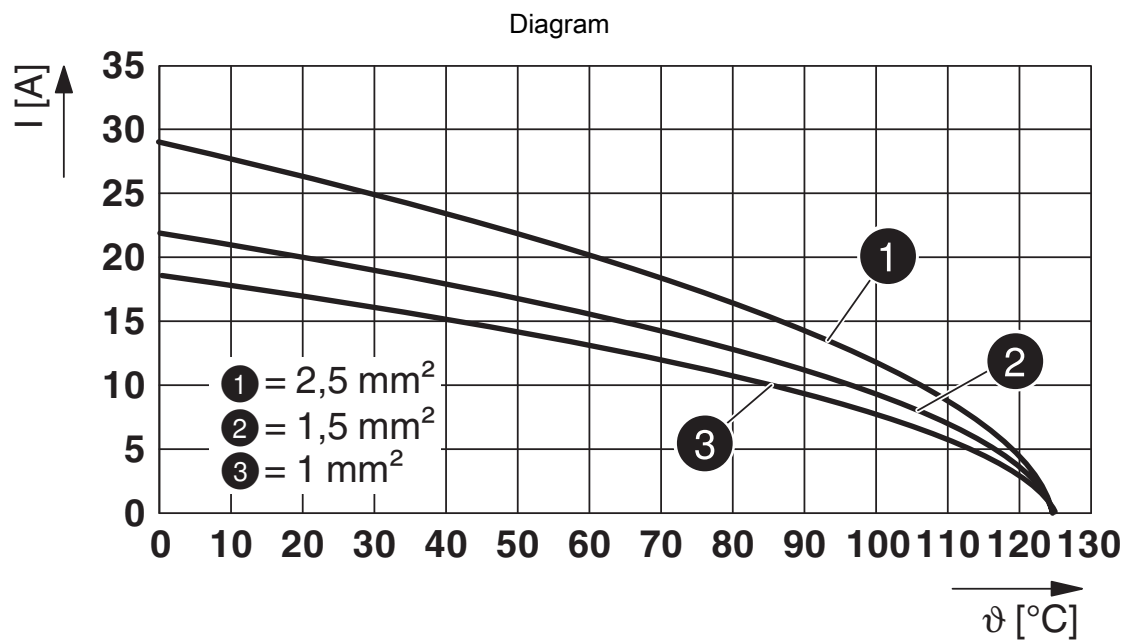

Derating diagram

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1585294>

DNV Approval ID: TAE000037S				
---------------------------------------	--	--	--	--

CSA Approval ID: 13631				
	Nominal voltage U _N	Nominal current I _N	Cross section AWG	Cross section mm ²
	600 V	15 A	- 14	-

UL Recognized Approval ID: E118976				
	Nominal voltage U _N	Nominal current I _N	Cross section AWG	Cross section mm ²
	600 V	19 A	-	-

EAC Approval ID: RU C-DE.BL08.B.00511				
---	--	--	--	--

UL Recognized Approval ID: E468743				
	Nominal voltage U _N	Nominal current I _N	Cross section AWG	Cross section mm ²
	600 V	18 A	-	-

HC-A10-I-UT-M - Contact insert



1585294

<https://www.phoenixcontact.com/us/products/1585294>

Classifications

ECLASS

ECLASS-11.0	27440205
ECLASS-12.0	27440205
ECLASS-13.0	27440205

ETIM

ETIM 9.0	EC000438
----------	----------

UNSPSC

UNSPSC 21.0	39121500
-------------	----------

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



Environmental product compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



Accessories

CP-HC-S - Coding profile

1410916

<https://www.phoenixcontact.com/us/products/1410916>

Coding profile, for contact inserts HC-BB... / HC-A10... / HC-A16...



HC-CB - Coding bolt

1772722

<https://www.phoenixcontact.com/us/products/1772722>

Coding pin, prevents mismating of up to six connectors with an identical number of positions



HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



HC-CST - Coding element

1676857

<https://www.phoenixcontact.com/us/products/1676857>



Coding peg for coding up to 16 connectors

HC-CBU - Coding element

1676860

<https://www.phoenixcontact.com/us/products/1676860>



Coding socket for coding up to 16 connectors

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



HC-A-PES - Screw

1584868

<https://www.phoenixcontact.com/us/products/1584868>

PE screw for contact inserts of A series




HC-A10-I-UT-F - Contact insert

1585304

<https://www.phoenixcontact.com/us/products/1585304>

Contact insert, number of positions: 10+PE, size: D15, number of connections per position: 1, Socket, Screw connection, 250 V, 16 A, 0.5 mm² ... 2.5 mm²

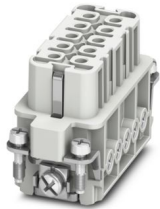

HC-A10-I-UT-M - Contact insert

1585294

<https://www.phoenixcontact.com/us/products/1585294>



HC-A-PE-PT - Adapter

1054712

<https://www.phoenixcontact.com/us/products/1054712>



PE adapter with PT connection, for 1 PE connection, for HC-A10 / HC-A16 / HC-D15 / HC-D25 series contact inserts

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com