

SBT Series
[RoHS Compliant]




• Tape and Reel Dimensions (see page 28)

Model	Rated voltage DC (V)	Rated current (mA)	Inductance (1kHz, 70mA) (μH)	DC resistance (mΩ) max.	Operating temperature range (°C)	Packaging
SBT-0208□	50	500	8±50%	20	-25~+70	Bulk (100pcs.)
SBT-0210□	50	500	10±50%	20	-25~+70	
SBT-0240□	50	500	40±35%	34	-25~+70	
SBT-0260□	50	500	60±35%	50	-25~+70	


• □Taping (2000 pcs./ reel x 6), ▢Flat taping (1000pcs./ box x 10)

Shape and Dimensions

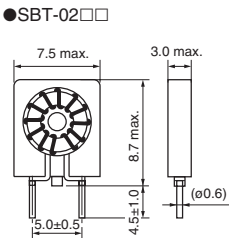

[mm]

Impedance vs. Frequency

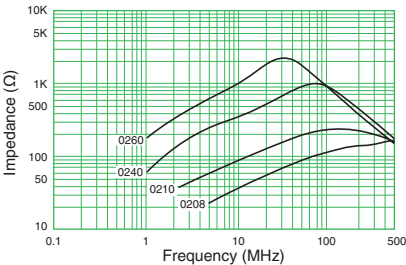


- All specifications in this catalog and production status of products are subject to change without notice. Prior to the purchase, please contact TOKIN for updated product data.
- Please request for a specification sheet for detailed product data prior to the purchase.
- Before using the product in this catalog, please read "Precautions" and other safety precautions listed in the printed version catalog.

Tape and Reel Dimensions


SBT Series

Tape and Reel Dimensions

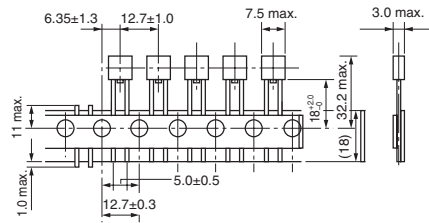

SNT Series

Tape and Reel Dimensions

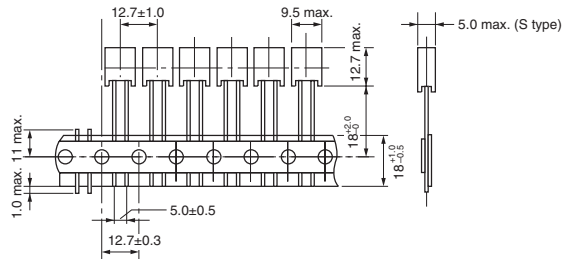

- All specifications in this catalog and production status of products are subject to change without notice. Prior to the purchase, please contact TOKIN for updated product data.
- Please request for a specification sheet for detailed product data prior to the purchase.
- Before using the product in this catalog, please read "Precautions" and other safety precautions listed in the printed version catalog.