


RoHS
Halogen-Free

Edition	Modifier	Date	Description	ECN No.

A

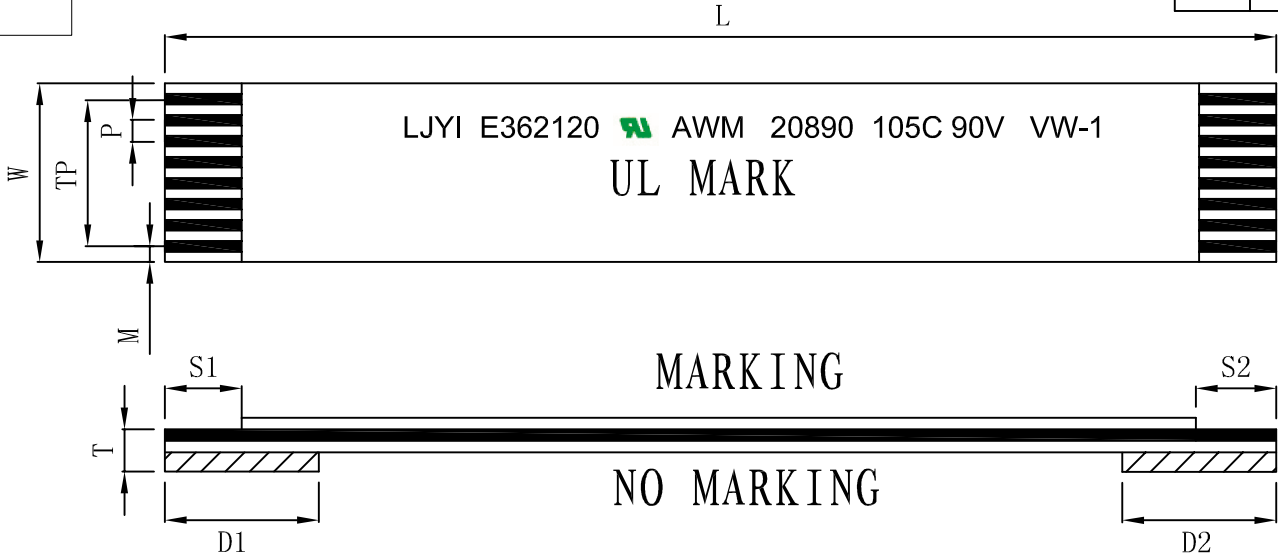


B

C

Item	Code	Spec	
NO of PIN	N	6	
Pitch	P	0.5±0.05	
Total Length	L	76±1	
Margin	M	0.5±0.05	
Thickness	T	0.3±0.03	
Strip Length	S1	3.5±0.5	
	S2	3.5±0.5	
Supporting Length	D1	6.0±1.0	
	D2	6.0±1.0	
Total Pitch	TP	2.5±0.05	
Total Width	W	3.5±0.05	
Conductors	Width	0.3±0.03	
	Thickness	0.035±0.005	
	Plated	Sn(1um)	Min
Film	White	0.06mm	
	White	0.06mm	
Supporting	Blue	0.225mm	
UL NO.	UL20890(105℃ 90V)		

Processing requirement:

1.			
NO.	Specification description	Number	Remarks

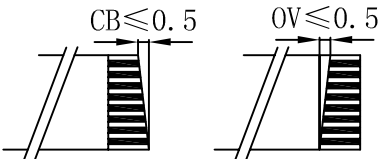

CnC Tech, LLC			
Industrial Cable and Connector Technology			
DRAWN BY:	DATE:	DESCRIPTION:	
	2018/07/20	6-76-0.5-3.5/3.5-6/6-A-Tin	
CHECKED BY:	SHEET 1 of 1	ITEM NO. 310-06-0076	
APPROVED BY:	SCALE 1:1	REV. A/0	UNIT: mm

A

B

C