

MLCC > Normal Type

CL10B105KP8NNN#

Mass Production

General

Standard

2T 

Lineup Normal

125°C

N/A

RoHS

REACH

?

"#" indicates a package code.

List of part numbers with package codes 

CL10B105KP8NNNC, CL10B105KP8NNND, CL10B105KP8NNNL


※ If the packaging code is Z or R, the horizontal package type (HMC) is applied to reduce the acoustic noise.

Simulation >

Inquiry >

Size


Size Code	0603 (1608)	※ Inch(mm)
L Size	1.60±0.10mm	
W Size	0.80±0.10mm	
T Size	0.80±0.10mm	

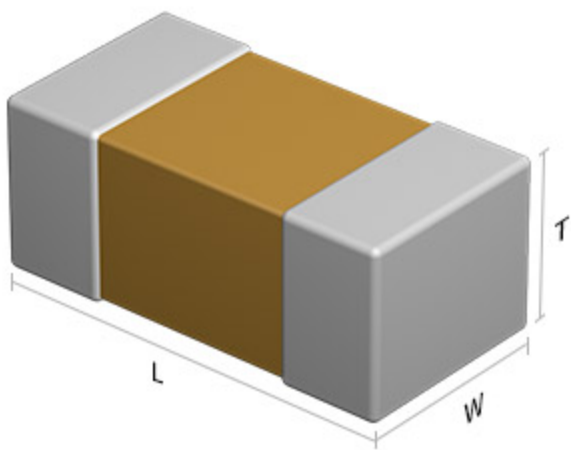

Characteristics

Temperature Characteristic	X7R(-55 ~ +125)
Capacitance	1.0uF
Tolerance	±10%
Rated Voltage	10.0Vdc
Status	Mass Production

Graph

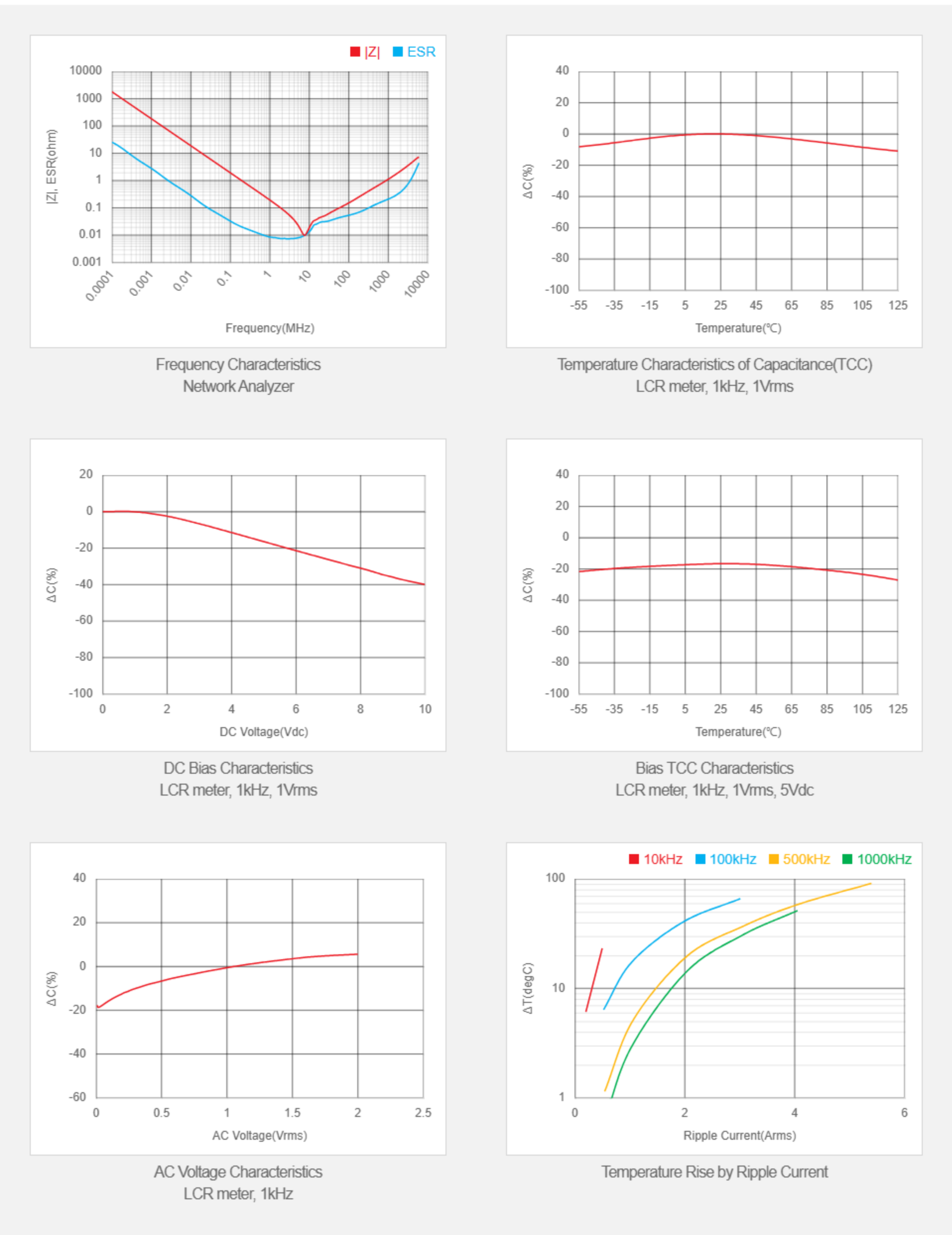



Any data in this page are subject to change, modify or discontinue without notice.

This page includes the typical data for design reference only.

If there is any question regarding the data, please contact our sales personnel or application engineers.

Download This Page (.PDF) 

Data

Specsheet

Datasheet

S2P & SPICE

SnapMagic Symbol, Footprint, 3D Mod

Recommended For You

Part Search Tool

Product Search

Simulation Tool

Component Library

Technical Data Archive

Software Library

Sales Partners

Product Environmental Certificate

Certificate

Latest Newsletter