


SKINDICHT® SVRE

SKINDICHT® SVRE, PG cable gland with incised sealing ring and hexagonal fitting

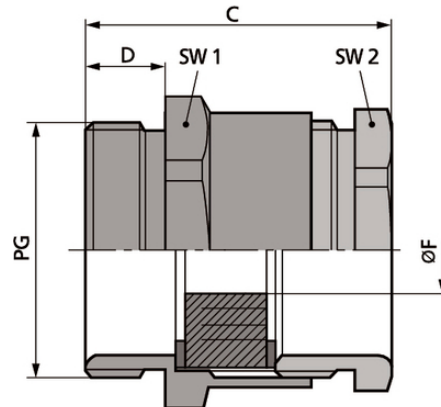

Robust

Benefits

With incised sealing ring for adjustment to several cable diameters
Fewer sizes need to be kept in stock

Application range

Brass cable gland with hexagonal fitting and variable incised sealing ring.

Product Make-up

PG connection thread

Note

Refer to SKINDICHT® EV for additional accessories
Counter nut to be used: SKINDICHT® SM

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 Class-Description: Cable screw gland

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class-Description: Cable screw gland

Caution:

The installation dimensions
can be found in appendix T21

On request:

Available with long connection thread
Available with PG 11 to 36 with FKM incised ring

Material:

Body: nickel-plated brass
Incised seal: CR

Last Update (17.04.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINDICHT® SVRE

Protection rating:	IP 54
Temperature range:	-20°C to +80°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SKINDICHT® SVRE

Article number	Article designation / size	Incised sealing ring ØF (mm)	SW1/SW2 mm	Overall length C mm	Thread length D mm	Pieces / PU
SKINDICHT® SVRE						
52005540	SVRE 9	5/8	17.0 / 15.0	22.6	6	100
52000310	SVRE 11	7/10/12.5	20.0 / 18.0	22.6	6	50
52000320	SVRE 13,5	7/10.5/13/16	22.0 / 20.0	26.1	6.5	50
52000330	SVRE 16	8/10.5/13.5/16	24.0 / 22.0	27.1	6.5	50
52000340	SVRE 21	11/15/18/20	30.0 / 28.0	29.6	7	50
52000350	SVRE 29	19/23/27/31	40.0 / 37.0	32.6	8	50
52000360	SVRE 36	25/28/31/35	50.0 / 47.0	38.6	9	20
52005550	SVRE 42	35.5/39/42.5/46	57.0 / 54.0	43.6	10	10
52005560	SVRE 48	40.5/44/47/50.5	64.0 / 60.0	45.1	10	10