

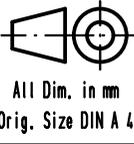
SPECIFICATIONS

Filter type	C
Capacitance	470 pF±20%
Working voltage	100 V
Current rating	6,5 A

Minimum insertion loss

FREQUENCY (MHz)	ATTENUATION (dB)
5	-
10	1
50	10
100	15
500	35
1000	32

Note: Jack-screws are not pre-mounted to allow mounting from any ends

A						 All Dim. in mm Orig. Size DIN A 4	Male / Female D-Sub filter adapter, 25 poles, 470 pF	Maßstab/ Scale 1,5:1		
				Detail.	03/09/07				JS	
				Insp.						
				Stand.						
	34901	01/04/08	BB							
	34894	12/03/08	PK							
		03/09/07	JS							
	Mod.	Dot.	Name	HARTING EURL F-95972 Paris			TB 09 64 300 7220	Blatt/ Page 1 / 1		
									Sub.	