



+ SHIPS FREE
UPS FLAT RATE
MILITARY
DISCOUNT
IBEW-NECA
DISCOUNT

[Contact Us](#)

[Account](#) | [Wishlist](#) | [Quick Order](#) | [Log In](#)

100% Lifetime Guarantee

- [Home](#)
- [Torx](#)
- [Torque Tools](#)
- [Tech Tools](#)
- [Shop Tools](#)
- [Screwdrivers](#)
- [Pliers](#)
- [Insulated](#)
- [Hex](#)
- [ESD Safe](#)
- [Bits & Sets](#)
- [Catalogs](#)
- On Sale**

Home → Tool Types → Sockets → Insulated Metric Sockets 3/8" Drive

Insulated Metric Sockets 3/8" Drive



Zoom

Titles and descriptions supersede the photo. We typically use the same image for different sizes of tools.

[Be the first to review this product](#)

Filter:

SKU	Product	Sockets Metric Sizes	Price	Qty
31506	Insulated Socket 3/8" Drive 6mm	6.0mm		0
31507	Insulated Socket 3/8" Drive 7mm	7.0mm		0
31508	Insulated Socket 3/8" Drive 8mm	8.0mm		0
31509	Insulated Socket 3/8" Drive 9mm	9.0mm		0
31510	Insulated Socket 3/8" Drive 10mm	10.0mm		0
31511	Insulated Socket 3/8" Drive 11mm	11.0mm		0
31512	Insulated Socket 3/8" Drive 12mm	12.0mm		0
31513	Insulated Socket 3/8" Drive 13mm	13.0mm		0
31514	Insulated Socket 3/8" Drive 14mm	14.0mm		0
31515	Insulated Socket 3/8" Drive 15mm	15.0mm		0

SKU	Product	Sockets Metric Sizes	Price	Qty
31516	Insulated Socket 3/8" Drive 16mm	16.0mm		0
31517	Insulated Socket 3/8" Drive 17mm	17.0mm		0
31518	Insulated Socket 3/8" Drive 18mm	18.0mm		0
31519	Insulated Socket 3/8" Drive 19mm	19.0mm		0
31520	Insulated Socket 3/8" Drive 20mm	20.0mm		0
31521	Insulated Socket 3/8" Drive 21mm	21.0mm		0
31522	Insulated Socket 3/8" Drive 22mm	22.0mm		0
31524	Insulated Socket 3/8" Drive 24mm	24.0mm		0

Add to Cart

- Add to Wishlist
 Share on Facebook
 Tweet This
 Pin it



Frequently bought together



Price for all selected : [Add selected to cart](#)

This item: [Insulated Metric Sockets 3/8" Drive](#)

- [Universal Rail System Holds 16-20 Clips](#)
- [Socket Storage Clips For 3/8" Drive Sockets - 10 Pack](#)

Details

Meets ASTM F1505, EN/IEC 60900, NFPA-70E, CSA, VDE, Insulation specifications

Each Tool individually tested to 10,000 Volts

Certified to 1000 Volt AC or 1500 Volt DC

Protective Insulation Molded Directly onto the Socket

Double Covered Insulation Red Over Yellow

High Visibility Coatings

chrome-vanadium-molybdenum Hardened Tool Steel

Forged and Oil-Hardened

Additional Info

Head Type	hex metric
Country of Manufacture	Germany
Socket Type	Insulated
Socket Drive Size	3/8" Square

WRITE YOUR OWN REVIEW


Only registered users can write reviews. Please, [log in](#) or [register](#)

Warranty Info

Wiha Products Carry a **100% Satisfaction Guarantee**. All Wiha tools are guaranteed to be free of defects in workmanship and materials and will be replaced if found to be deficient providing tools have not been altered or misused. Wiha Insert Bits, Power Bits, Ceramic Tools and Tweezers are not warranted for use. Wiha Brand Torque control Tools are warranted for twelve months from date of purchase up to 5,000 torque Cycles.

[View Full Warranty](#)

You may also be interested in the following product(s)

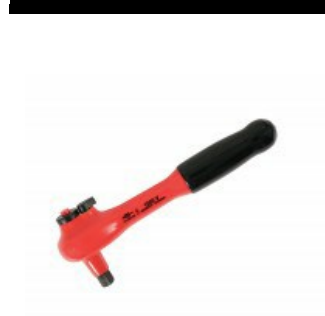

Insulated Ratchet 3/8" x 190mm

Wiha Professional Quality Hand Tools



We produce Wiha products around the world under strict ISO quality standards. State of the art technology and special tool steels

assure products consistent with our reputation for outstanding performance in demanding service, repair and production applications.

[Discounts and promotions](#)

[Military Discount](#)

[IBEW-NECA Discount](#)

[Filter and sort all Wiha hand tools](#)

[Complete list of tools](#)

Wiha Tools USA Since 1985

Wiha Activities In the USA Started in August of 1985 bringing Wiha quality to professional tool users in North America. Our USA warehouse and distribution center services all 50 states & Our New Facilities In Canada Supply millions of tools from stock to professional quality conscious tool users throughout North America.

[About Us](#)

[Privacy Policy](#)

[Terms and Conditions](#)

[Having technical issues with the website?](#)

We accept

amazon pay

Wiha Tools USA Willi Hahn Corporation

A Subsidiary of [Wiha Werkzeuge Gmbh](#)
[Schonach Germany](#)

**Monday - Friday Office Hours 7am - 5pm
CST USA**

1348 Dundas Cir,

Monticello, MN 55362

Customer Service Email:

cservice@wihatools.com

Tel: 763-295-6591

Fax: 763-295-6598

[Shipping](#)

[Returns](#)

[Warranty Info](#)

[About Us](#)

[Privacy Policy](#)

[Terms and Conditions](#)

**Over 5000 Professional Quality Wiha Tools
In Stock**



Newsletter

Subscribe