




You are here: [Home](#) ▶ [Magnetic Buzzer](#) ▶ [Magnetic Indicator](#) ▶ [Pin](#) ▶ KXG1212C


KXG1212C

[Print](#)


VOLTAGE-SOUND PRESSURE
LEVEL

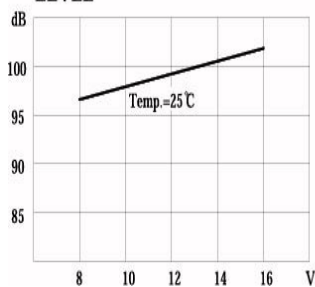

VOLTAGE-CURRENT
CONSUMPTION

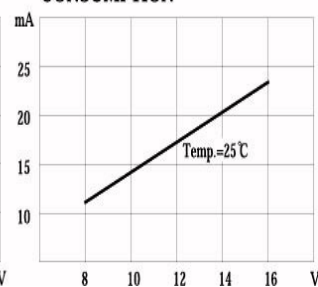

Additional Info

Rated Frequency (Hz):	2,300+/-300
Rated Voltage (Vo-p/VDC):	12.0
Current Consumption (mA):	Max. 35
Sound Pressure Level (dB):	Min. 85dBA(Typical 94)@10cm
Operating Voltage Range (Vo-p):	8.0~16.0
Operating Temperature (°C):	-30~+70
Storage Temperature (°C):	-40~+85
Dimension (mm):	φ12.0x9.5
Sound Demonstration:	click here

 [Like](#) [Sign Up](#) to see what your friends like.

Tagged under [Indicator](#) [Pin](#) [Internal Circuitry](#) [Type 80VDC](#)

More in this category: [« KXG1212C-B](#) [KXG1606C »](#)

[back to top](#)

Best view with [Microsoft Internet Explorer 9](#) or above, [Mozilla Firefox](#) or [Google Chrome](#).

版權所有 © 2016 志豐電子 251新北市淡水區中正東路2段69-11號10樓 Tel :+886-2-2809-5651 info@kingstate.com.tw

Copyright © 2016 Kingstate Electronics Corp. 10F, No. 69-11, Sec.2, JhongJheng E. Rd.,Damshui Dist, New Taipei City 251, Taiwan