


37306300410 - 373 Series

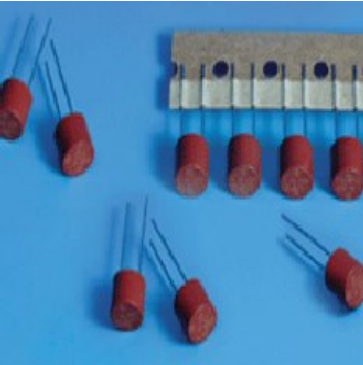

Series: 373

Fuse 373 Datasheet

Disclaimer Notice

The 373 Series are TR5®, sub-miniature, fast-acting type, 250V rated fuses, designed in accordance to UL 248- 14.

Features:

- Reduced PCB space requirements
- Direct solderable or plug-in versions
- Internationally approved
- Low internal resistance, Shocksafe casing
- Vibration resistant
- Halogen free
- CCCe for China import

Questions? [Contact Littelfuse Support](#)

Check Stock

Order Samples

NEW!
Product Selection Guide eCatalog
[Read Now](#)

Electronics
News and Information

SIGN UP NOW

Feedback

Electrical Characteristics	Technical Resources	Environmental Info
Property (Mouseover for details)	Value	
Ampere Rating (A)	0.63	
Nominal Melting I²T (A²sec)	0.045	
Interrupting Rating	50A@250VAC	
Min Operating Temp °C	-40	
Max Operating Temp (°C)	85	
Moisture Sensitivity Level	MIL-STD-202 Method 106	
Nominal Power Dissipation (W)	135	
Nominal Voltage Drop (mV)	210	
Nominal Cold Resistance (Ohms)	0.118	
Opening	Fast-Acting (F)	
Package Size	TR5 (8.5x8mm)	
VAC (V)	250	

Connect with Littelfuse

Sign up to receive special offers and news

Enter your email

Submit

For more details about how we use your information, check our [Privacy Statement](#).



Mobile Site

About Littelfuse

- About Littelfuse
- Conflict Free Statement
- History
- Investor Relations
- Legal
- Press Room
- Privacy Statement
- Supply Chain Transparency
- Website Feedback

Explore Littelfuse

- Capabilities Brochures
- Careers
- Check Distributor Stock
- Competitor Cross Reference
- Industries
- Order Samples
- Products
- Services

Technical Resources

- Application Designs
- Education
- FAQs
- iDesign™
- Littelfuse University
- Product Catalogs
- Quality Documents
- Technical Documents

