


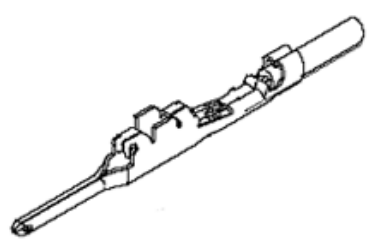

Part Number : 506609001
Product Description : 1.00mm Crimp Pin
Terminal, Pre-Tinned Brass
Series Number : 50660
Status : New Business Not Supported
Product Category : Crimp Terminals



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
--------	----------------------------

Category	Crimp Terminals
Series	50660
Description	1.00mm Crimp Pin Terminal, Pre-Tinned Brass
Application	Power
Product Name	N/A
UPC	800753863170

Physical

Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	1.60-1.40mm
Wire Size (AWG)	20, 22
Wire Size mm ²	0.30-0.50

This document was generated on Mar 02, 2025