




Mating Cycles	500
Filter type	C
Capacitance	1000pf±20%
Working Voltage	100V
Current rating	7.5 A
Insulation Resistance	>1GΩ

FREQUENCY (MHz)	ATTENUATION dB
5	1 dB
10	3dB
50	12dB
100	20dB
500	34dB
1000	30dB

All Dim. in mm
Orig. Size DIN A 4

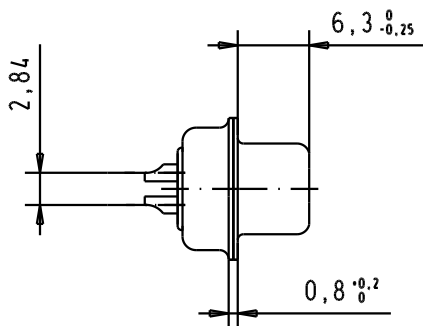