




**TERMINALS & SPLICES**

**CRIMP RINGS & SPADES**

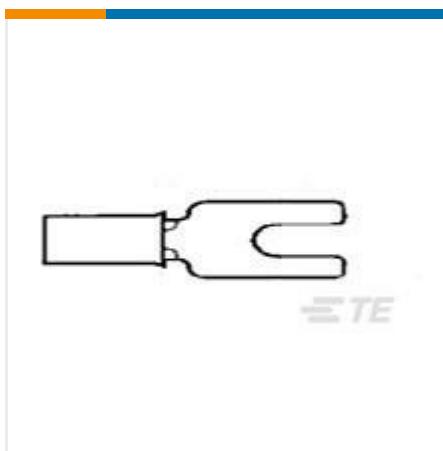

✓ Active

**TE CONNECTIVITY (TE)**

## **SOLIS 16-14 SPADE #8**

**SOLISTRAND | SOLISTRAND**

**130534**

TE Internal Number: 130534

Alias ID: 100420-000, AMPS-0-0130534-0

**EU RoHS Compliant**

**EU ELV Compliant**

**Terminal Type** Spade Tongue

**Stud Diameter** 4.3 mm [.169 in]

**Tongue Thickness** .8 mm [.031 in]

**Sealed** No

**Heavy Duty** No

**PRODUCT DRAWING**

English

**DOCUMENTATION**

Product Drawings

### **COSSE FOURCHE**

PDF ([TIFF AVAILABLE](#))

English

Product Environmental Compliance

TE Material Declaration

### **MD\_130534\_092920151155\_dmtec**

PDF

English

Agency Approvals

UL Report

### **Plastic-Grip, Solistrand, DG, And PIDG Terminals**

PDF

English

UL

## Plastic-Grip And Solistrand Terminal, Butt And Parallel Connectors

PDF

English

### FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

#### Product Type Features

**Sealed** No

**Barrel Type** Closed Barrel

**Wire/Cable Type** Regular Wire

**Insulated** No

**Insulated Wire Support** No

**Stud Size** 8, M4

**Shape Code** SPADE-047

#### Configuration Features

**Terminal Angle** Straight

#### Body Features

**Plating Material** Tin

**Inspection Slot** No

**Plating Thickness** 2.54  $\mu\text{m}$  [ 100  $\mu\text{in}$  ]

#### Contact Features

**Terminal Type** Spade Tongue

**Terminal Orientation** Straight

#### Dimensions

**Stud Diameter** 4.3 mm [ .169 in ]

**Tongue Thickness** .8 mm [ .031 in ]

**Wire Size (AWG)** 17 – 13

**Wire Size (mm<sup>2</sup>)** 1 – 2.5

**Barrel Inside Diameter** 2.15 mm [ .085 in ]

**Material Thickness** .79 mm [ .0311 in ]

**Overall Length** 14.9 mm [ .59 in ]

#### Operation/Application

**Heavy Duty** No

#### Industry Standards

**Government Qualified** No

Packaging Features

Packaging Method Box

Packaging Quantity 1000

Statement of Compliance

**Statement of Compliance**

PDF

---