

SMD terminal block with push-buttons in tape-and-reel packing; 2-pole; Pin spacing 4 mm / 0.157 in

Item No.: 2060-422/998-404



SMD terminal block with push-buttons in tape-and-reel packing; 2-pole; Pin spacing 4 mm / 0.157 in

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	2060-422/998-404
GTIN / EAN	4050821530985
Content	1
Order amount	1,000
Customer item number	

Notes

SMD terminal blocks with CAGE CLAMP® S and push-buttonsHeight of just 4.5 mm minimizes on-board LED shadowingAvailable in tape-and-reel packaging for automated assembly

Technical data

Miscellaneous

No. of Poles	2
Total number of connection points	2
Total number of potentials	2
Color	black
Ratings according to 1	IEC/EN 60664-1
Overvoltage category EN 1	III
Pollution degree (1)	2
Rated voltage EN (1) [V]	160 [V]



Technical data	
Rated surge voltage (1) [kV]	2.5 [kV]
Nominal current [A]	9 [A]
Overvoltage category EN 2	II
Degree of pollution (2)	2
Rated voltage EN (2) [V]	320 [V]
Rated surge voltage (2) [kV]	2.5 [kV]
Nominal current (2) [A]	9 [A]
Overvoltage category EN 3	III
Degree of pollution (3)	3
Rated voltage EN (3) [V]	63 [V]
Rated surge voltage (3) [kV]	2.5 [kV]
Nominal current (3) [A]	9 [A]
Connection technology (1)	CAGE CLAMP® S
Conductor type (1)	solid
Cross section from (1) [mm²]	0.2 [mm²]
Cross section up to (1) [mm²]	0.75 [mm²]
Cross section from (1) [AWG]	24 [AWG]
Cross section up to (1) [AWG]	18 [AWG]
Conductor type (2)	fine-stranded
Cross section from (2) [mm²]	0.2 [mm²]
Cross section up to (2) [mm²]	0.75 [mm²]
Cross section from (2) [AWG]	24 [AWG]
Cross section up to (2) [AWG]	18 [AWG]
Conductor type (3)	fine-stranded (with insulated ferrule)
Cross section from (3) [mm²]	0.25 [mm²]
Cross section up to (3) [mm²]	0.34 [mm²]
Conductor type (4)	fine-stranded (with uninsulated ferrule)
Cross section from (4) [mm²]	0.25 [mm²]
Cross section up to (4) [mm²]	0.34 [mm²]
Stripped length from (1) [mm]	6 [mm]
Stripped length up to (1) [mm]	7 [mm]
Strip length from [inch] [in]	0.24 [in]
Strip length up to [inch] [in]	0.28 [in]
Stripped length (1) [in]	0.26 [in]

Technical data	
Material group	I
Insulating material	Polyphthalamide glass fiber (PPA-GF)
Flammability rating per UL 94	V0
Lower limit temperature [C]	-60 [C]
Upper temperature limit [C]	105 [C]
Contact material	Copper alloy
Contact plating	tin-plated
Weight [g]	0.888 [g]
Width [mm]	7.9 [mm]
Width [in]	0.311 [in]
Height [mm]	4.5 [mm]
Height [in]	0.177 [in]
Length [mm]	13.1 [mm]
Length [in]	0.516 [in]
Pin spacing from [mm]	4 [mm]
Pin spacing from [in]	0.157 [in]

Approbation					
Item No.	Registration	Registration no.	Voltage [V]	Current [A]	Cross section [mm², AWG]
2060-422/998-404	CCA	2165051.01	320	9	0.25-0.75
2060-422/998-404	CCA	2171408.02	320	9	0.25-0.75
2060-422/998-404	UL	E45171	250	9	

Images & drawings



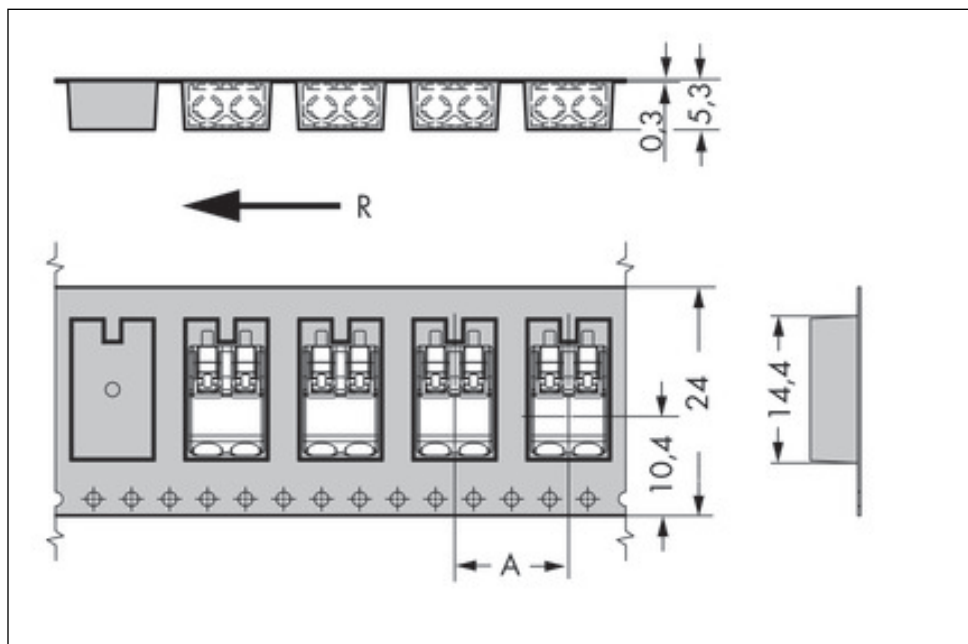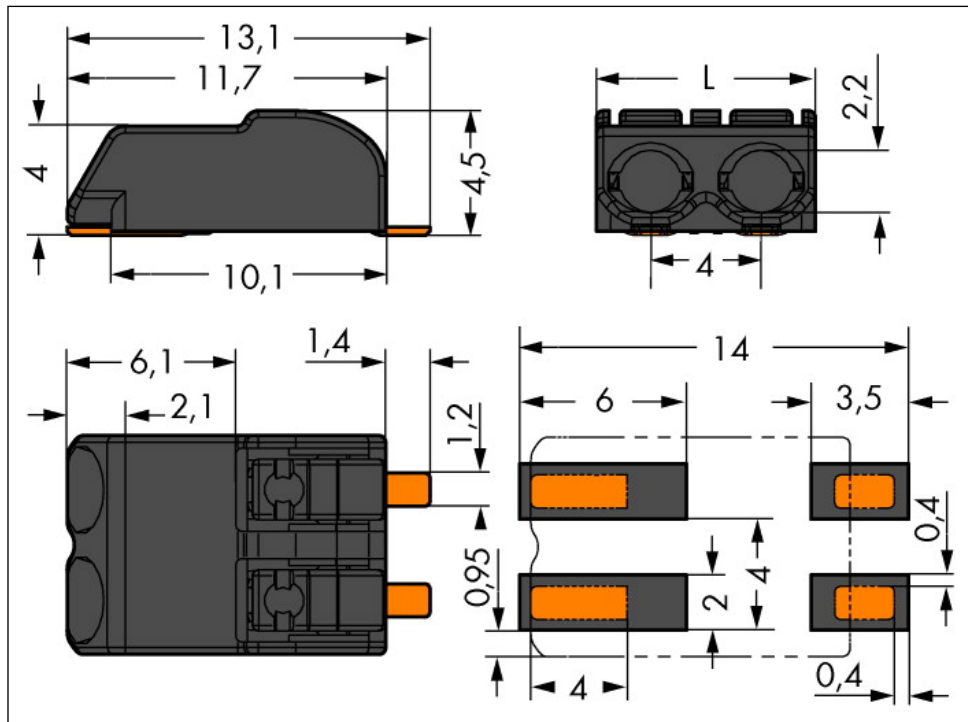

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.