


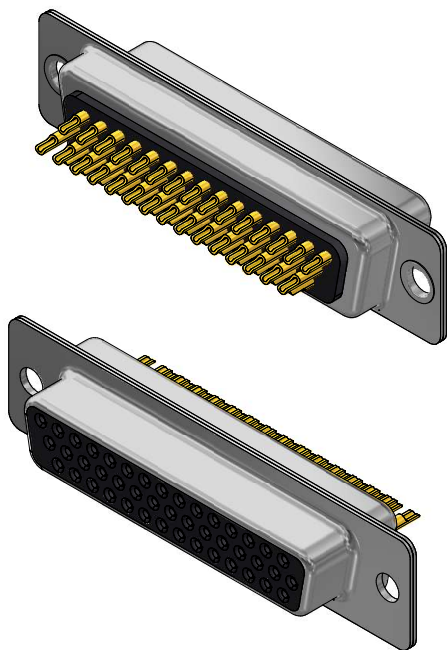

Technical specification/




Technische Daten:

Working voltage/ Betriebsspannung:	60 V AC/DC
Insulation resistance/ Isolationswiderstand:	min. 3000 MOhm
Dielectric withstanding voltage/ Spannungsfestigkeit:	1000 V AC / minute
Operating temperature/ Betriebstemperatur:	- 55 °C ... + 105 °C
Current rating/ Strombelastbarkeit:	3 A
Contact Resistance/ Durchgangswiderstand:	max. 15 mOhm

Materials/

Werkstoffe:

Contact/ Kontakt:	Cu alloy, Underplate/ 50 µin Nickel
	Beschichtung:
	Contact area/ Gold flash
	Kontaktbereich:
	Solder tails area/ Gold flash
	Lötbereich:
Shell/ Gehäuse:	Steel, Nickel plated
Rivet, Boardlock/ Befestigungsniet:	Copper alloy
Insulator/ Isolierkörper:	Thermal plastic UL 94 V-0

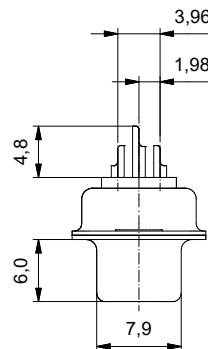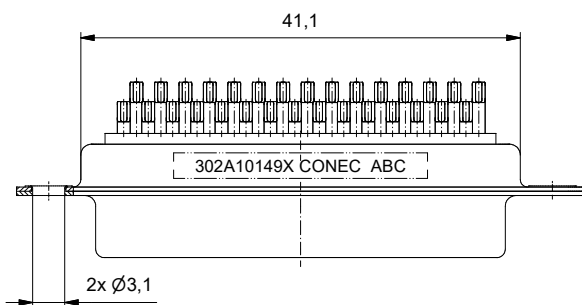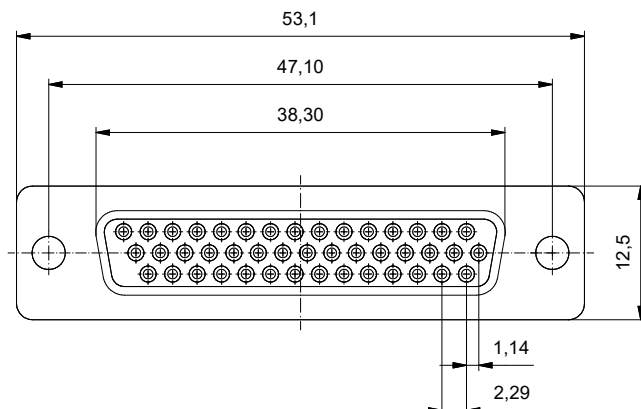

Part no. / Part marked/
Art.-Nr. / Bedruckung:

302A10149X

dim. in mm		D-SUB HD Female 44pos. solder cup stamped contacts D-SUB HD Buchsenleiste 44pol. Lötkehl gestanzte Kontakte	
general tolerance/ Allgemeintoleranz:	0, ±0.5 ,0 ±0.3 ,00 ±0.2	Date/Datum 04.07.2022	Name Bub
Index: a Original	Scale/ Maßstab: 2:1	appd./ gepr.: 22.08.2022	Lehmenkühler
RoHS compliant/ konform		dwg no / Z.-nr.:	16K1A4314
			DIN-A3 1 / 1

CONEC